



ROB 750


Special Applications

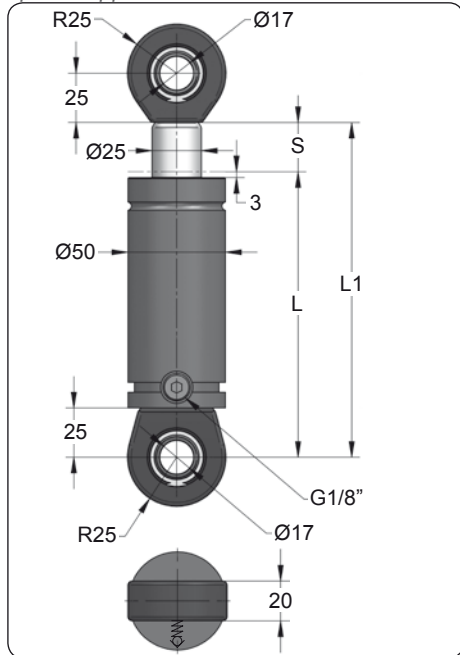

ORDER	S (mm)	L1 ±0,25 (mm)	L (mm)	Kg.
ROB 750 012	12.7	145.4	132.7	1.74
ROB 750 025	25	170	145	1.96
ROB 750 038	38	196	158	2.04
ROB 750 050	50	220	170	2.14
ROB 750 063	63.5	247	183.5	2.24
ROB 750 080	80	280	200	2.44
ROB 750 100	100	320	220	2.68
ROB 750 125	125	370	245	2.84
ROB 750 160	160	440	280	3.12

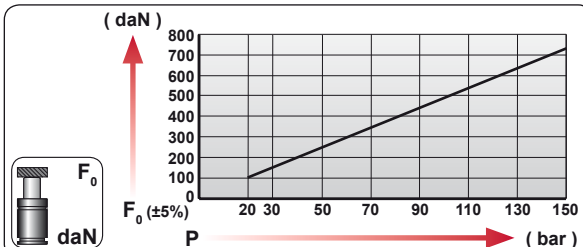

CODE					
		bar	psi		
ROB 750 050		150	2175	740	1100
-----		---	---	---	---

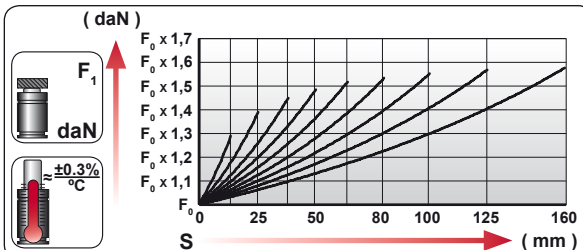

	ENG ORDER		
	DEU BESTELLUNG	daN	mm
	FRA COMMANDE		
	ITA ORDINE		
	ESP PEDIDO		
POR PEDIDO			

ROB 750 50

ROB 750 050

SEAL KIT S-XXXXXXX

CARTRIDGE KIT C-XXXXXXX

KIT S-XXXXXXX
KIT C-XXXXXXX

18 CG 1-Q

ENG REPAIR KIT	CHARGING ADAPTER
DEU ERSATZ	LADEADAPTER
FRA KIT DE RÉPARATION	RACCORD DE CHARGE
ITA KIT DI MANUTENZIONE	ADATTATORE DI CARICO
ESP KIT DE REPARACION	ADAPTADOR DE CARGA
POR KIT DE MANUTENÇÃO	ADAPTADOR DE CARGA

N ₂	S _{max} < 90%	V _{max} 1,6 m/s	P _{min} (20°C)	P _{max} (20°C)	T _{min}	T _{max}	600 CP-

bar	psi	bar	psi	°C	°F	°C	°F
20	290	150	2175	0	32	80	176