



ROB 5000


Special Applications

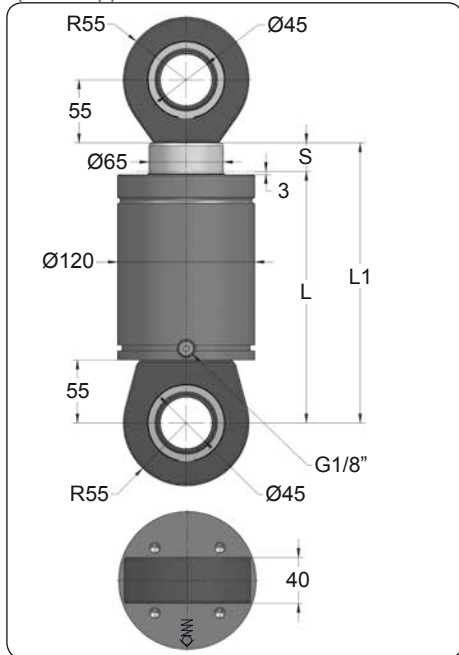

ORDER	S (mm)	L1 ±0,25 (mm)	L (mm)	Kg.
ROB 5000 012	12.7	220.4	207.7	15.79
ROB 5000 025	25	245	220	16.96
ROB 5000 038	38	271	233	17.11
ROB 5000 050	50	295	245	17.45
ROB 5000 063	63.5	322	258.5	18.17
ROB 5000 080	80	355	275	19.76
ROB 5000 100	100	395	295	20.21
ROB 5000 125	125	445	320	21.56
ROB 5000 160	160	515	355	23.36

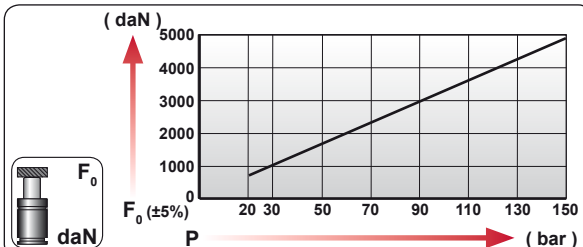

CODE					
		bar	psi	daN	daN
ROB 5000 050		150	2175	4980	7170
-----		---	---	---	---

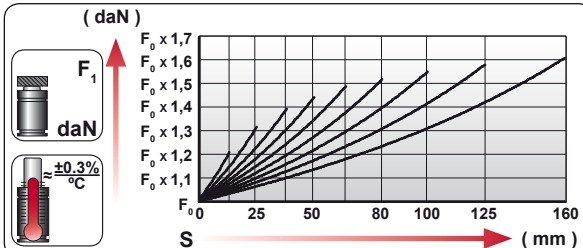

	ENG ORDER		
	DEU BESTELLUNG		
	FRA COMMANDE		
	ITA ORDINE		
	ESP PEDIDO		
POR PEDIDO			

ROB 5000 50

ROB 5000 050

SEAL KIT S-XXXXXXX	CARTRIDGE KIT C-XXXXXXX	
KIT S-XXXXXXX		18 CG 1-Q
KIT C-XXXXXXX		
ENG DEU REPAIR KIT ERSATZ	CHARGING ADAPTER LADEADAPTER	
FRA ITA KIT DE RÉPARATION KIT DI MANUTENZIONE	RACCORD DE CHARGE ADATTATORE DI CARICO	
ESP POR KIT DE REPARACION KIT DE MANUTENÇÃO	ADAPTADOR DE CARGA ADAPTADOR DE CARGA	

N ₂	Smax < 90%	Vmax 1,6 m/s	bar psi 20 290	bar psi 150 2175	°C °F 0 32	°C °F 80 176	600 CP-