



# EFGC 24

Gas Strippers

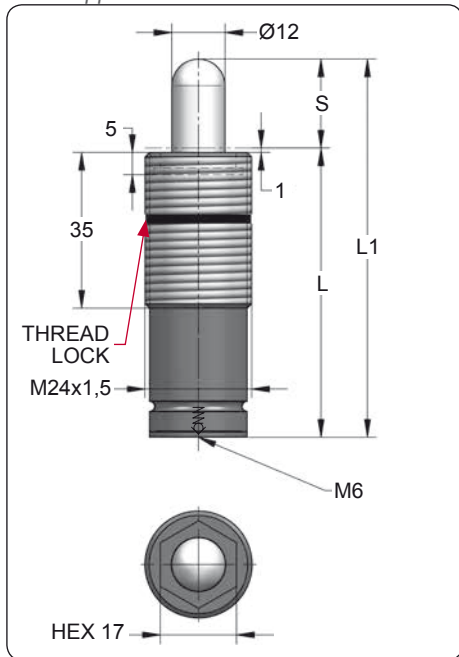


CODE	S (mm)	L1 ±0,25 (mm)	L (mm)	Kg.
EFGC 24 ... 010	10	65	55	0.15
EFGC 24 ... 020	20	85	65	0.17
EFGC 24 ... 030	30	105	75	0.18
EFGC 24 ... 040	40	125	85	0.20
EFGC 24 ... 050	50	145	95	0.22
EFGC 24 ... 060	60	165	105	0.24
EFGC 24 ... 070	70	185	115	0.26
EFGC 24 ... 080	80	205	125	0.28
EFGC 24 ... 100	100	245	145	0.32
EFGC 24 ... 125	125	295	170	0.36



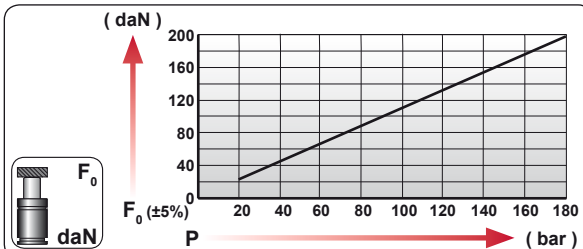
CODE	COLOR	Pressure		Force	
		bar	psi	daN	daN
EFGC 24 23 050	Green	20	290	23	40
EFGC 24 45 050	Blue	40	580	45	80
EFGC 24 85 050	Red	75	1090	85	150
EFGC 24 170 050	Yellow	150	2175	170	300
EFGC 24 XXX 050	Black	20-180	290-2610	23 - 200	40 - 350

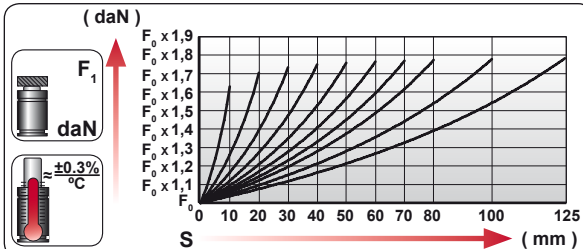

	ENG ORDER		
	DEU BESTELLUNG		
	FRA COMMANDE		
	ITA ORDINE		
	ESP PEDIDO		
POR PEDIDO			

**EFGC 24 200 50**

**EFGC 24 200 050**

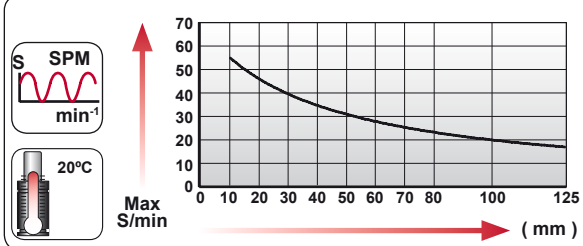




 
 

N <sub>2</sub>	S <sub>max</sub> < 90%	V <sub>max</sub> 1,6 m/s	P <sub>min</sub> (20°C)	P <sub>max</sub> (20°C)	T <sub>min</sub>	T <sub>max</sub>	

bar	psi	bar	psi	°C	°F	°C	°F	<b>X</b>
20	290	180	2610	0	32	80	176	

**LPT 17**



**E23-024**

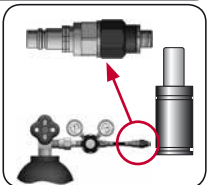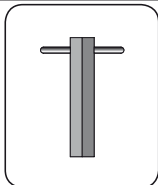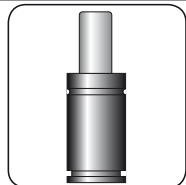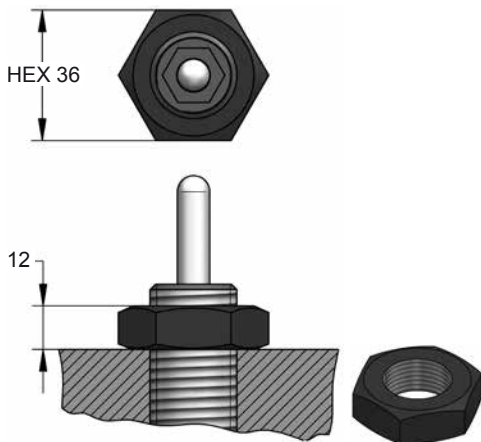

CODE	EFGC 24 200 050	<b>X</b>	LPT 17	06 CG 2-Q
ENG ORDER	GAS SPRING	REPAIR KIT	KEY	CHARGING ADAPTER
DEU BESTELLUNG	GASDRUCKFEDER	ERSATZTEILSATZ	MONTAGESCHLÜSSEL	LADEADAPTER
FRA COMMANDE	RESSORT À GAZ	KIT DE RÉPARATION	CLE	RACCORD DE CHARGE
ITA ORDINE	CILINDRO AD AZOTO	KIT DI MANUTENZIONE	CHIAVE	ADATTATORE DI CARICO
ESP PEDIDO	RESORTE DE GAS	KIT DE REPARACION	LLAVE	ADAPTADOR DE CARGA
POR PEDIDO	CILINDRO DE GÁS	KIT DE MANUTENÇÃO	CHAVE	ADAPTADOR DE CARGA