

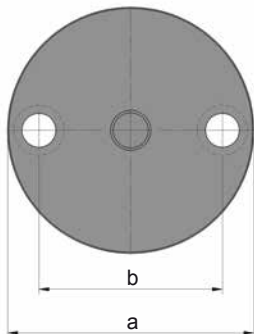


SPVW

39D 847

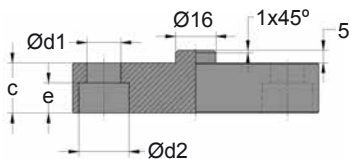

ORDER	Ø d _{max}	a (mm)	b (mm)	c (mm)	Ød1 (mm)	Ød2 (mm)	e (mm)
SPVW 001	50	98	73	20	13.5	20	12
SPVW 002	65	113	88	20	13.5	20	12
SPVW 003	80	128	103	20	13.5	20	12
SPVW 004	95	143	118	20	13.5	20	12


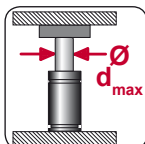


ENG ORDER		
DEU BESTELL		
FRA COMMANDE		
ITA ORDINE		
ESP PEDIDO		
POR PEDIDO		


SPVW 001

SPVW

39D 847

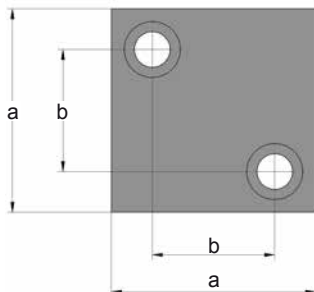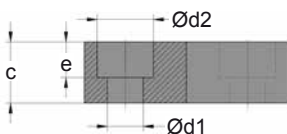

ORDER	Ø d _{max}	a (mm)	b (mm)	c (mm)	Ød1 (mm)	Ød2 (mm)	e (mm)
SPVW 010	20	40	24	12	7	11	7
SPVW 011	36	60	40	15	9	15	9
SPVW 013	80	100	74	20	11	18	11

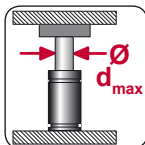

ENG ORDER		
DEU BESTELL		
FRA COMMANDE		
ITA ORDINE		
ESP PEDIDO		
POR PEDIDO		

SPVW 010