


Cable anchorage glands, CAG

- Description:** Two-component grommet with membrane seal and cable anchorage. The installation does not require tools, it is self-adjusting to its surrounding wall thickness and click-fixed in place. Because of its compact design it only extends 5.7 mm outside the enclosure on which it is mounted. The "pushout" membrane is a permanent seal until it is penetrated by a cable or pipe. Suitable for holes in materials of 0.7 to 3 mm thickness.
- Material:** TPE and polyamide 66, halogen free.
- Temperature resistance:** -20°C to +125°C.
- Finish:** RAL 7035.
- Protection:** IP 67,65, waterproof.
- Pack quantity:** 50 pieces.




H	H2	Metric	Diameter	Cable diameter (mm)	Hole diameter (mm)	Item no.
17-20	5.7	M20	34-37	7-11	20.5	CAG20
17-20	5.7	M25	39-42	7-13	25.5	CAG25

Front view

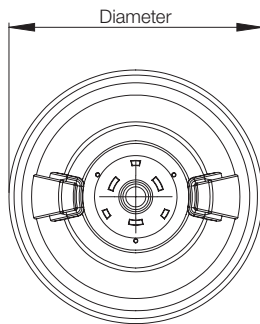

Side view

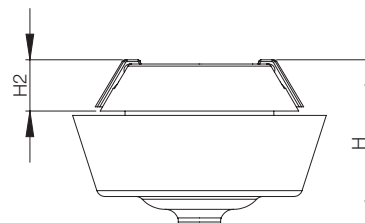

Cut-out

