

300-1000 mm

- Grab rail in robust, germ-reducing and easy-care stainless steel (AISI 304), satin finished.  
Further available surfaces: see below.
- Outer diameter of tubes 32 mm for ergonomic hold, clearance from wall 106 mm, bend radii 75 mm.
- Wall mountings with 8-point mounting plate – can be freely rotated, 4 mm thick with 2K-wall sealing-disc.
- Supports weight up to 125 kg.
- Concealed fixings 75 mm in diameter, anti-theft, with silicone sealing ring at tube joint.
- TÜV-certified in accordance with DIN EN 12182, CE-marked in accordance with 93/42 EEC.
- Mounting: With six screws.
- Delivery includes fixing material.
- Intermediate sizes available upon request.




### Suggested text for specifications:

Grab rail in stainless steel (AISI 304), outer diameter of tubes 32 mm, clearance from wall 106 mm, surface satin finished. Wall mountings with 8-point mounting plate – can be freely rotated, 4 mm thick with 2K-wall sealing-disc; supports weight up to 125 kg. Concealed fixings 75 mm in diameter, anti-theft, with silicone sealing ring at tube joint. TÜV-certified in accordance with DIN EN 12182, CE-marked in accordance with 93/42 EEC. Delivery includes fixing material.

Length ..... mm

Article No. BF600

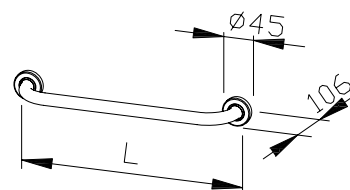

| Available surfaces        | Length / ID No. |         |         |         |         |
|---------------------------|-----------------|---------|---------|---------|---------|
|                           | 300 mm          | 400 mm  | 500 mm  | 600 mm  | 1000 mm |
| satin finished (standard) | 600 300         | 600 400 | 600 500 | 600 600 | 601 000 |
| textured                  | 600 310         | 600 410 | 600 510 | 600 610 | 601 010 |