


Sprężyny poliuretanowe

Polyurethane springs

Typ **SU-H**
Type

Przykład zamawiania:
Example order:

SU-H050080
95 ShoreA
D= 50mm
L = 80mm

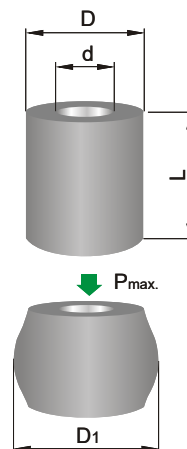

Średnica Diameter D [mm]	Max. obciążenie Max. Load [N]	d [mm]	D1 [mm]	95 Shore A													
				L [mm]													
				12	16	20	25	32	40	50	63	80	100	125	160		
				Obciążenie [N] na każdy mm ugięcia Load [N] for each mm of compression													
16	1950	6,5	21,3	650	487	390	310										
20	2800	8,5	26,6		700	560	450	350									
25	4220	10,5	33,3			844	675	527	422								
32	7560	13,5	42,6					945	756	605	480						
40	12000	13,5	53,2					1500	1200	960	760	600					
50	18900	18,0	66,5					2362	1890	1510	1200	945	756				
63	30000	18,0	83,8					3750	3000	2400	1900	1500	1200	960			
80	56000	21,0	106,4					7000	5600	4480	3550	2800	2240	1790			
100	84000	21,0	133,0					10500	8400	6720	5340	4200	3360	2690			
125	120000	27,0	166,3					15000	12000	9600	7620	6000	4800	3840	3000		
Max. ugięcie [mm] Max. compression [mm]			25%	3,0	4,0	5,0	6,3	8,0	10,0	12,5	15,8	20	25,0	33,1	40,0		