


Wypychacz odsadzany azotowany

Step pin nitrided

ESM

DIN 1530-2 / ISO 8694

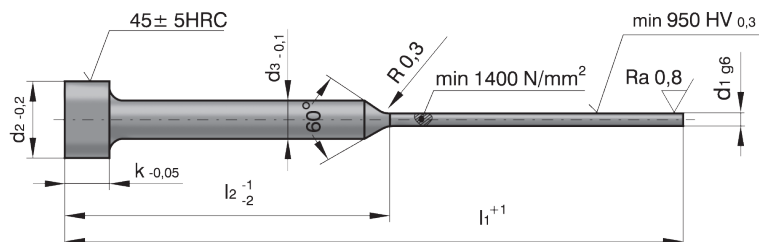

DIN 1530
Azotowany / Nitrided
Mat:
Stal narzędziowa
do pracy na gorąco
Hot working tool steel
500-550°C

d1	d2	d3	k	NR KAT.				
				l2=35 l1=80	l2=50 l1=100	l2=50 l1=125	l2=75 l1=160	l2=75 l1=200
0,8	4	2	2	ESM-0835080	ESM-0850100	ESM-0850125	ESM-0875160	
0,9				ESM-0935080	ESM-0950100	ESM-0950125	ESM-0975160	
1,0				ESM-1035080	ESM-1050100	ESM-1050125	ESM-1075160	
1,1				ESM-1135080	ESM-1150100	ESM-1150125	ESM-1175160	
1,2				ESM-1235080	ESM-1250100	ESM-1250125	ESM-1275160	
1,3				ESM-1335080	ESM-1350100	ESM-1350125	ESM-1375160	
1,4				ESM-1435080	ESM-1450100	ESM-1450125	ESM-1475160	
1,5							ESM-1535080	ESM-1550100
1,6	6	3	3	ESM-1635080	ESM-1650100	ESM-1650125	ESM-1675160	ESM-1675200
1,7				ESM-1735080	ESM-1750100	ESM-1750125	ESM-1775160	ESM-1775200
1,8				ESM-1835080	ESM-1850100	ESM-1850125	ESM-1875160	ESM-1875200
1,9				ESM-1935080	ESM-1950100	ESM-1950125	ESM-1975160	ESM-1975200
2,0				ESM-2035080	ESM-2050100	ESM-2050125	ESM-2075160	ESM-2075200
2,1				ESM-2135080	ESM-2150100	ESM-2150125	ESM-2175160	ESM-2175200
2,2				ESM-2235080	ESM-2250100	ESM-2250125	ESM-2275160	ESM-2275200
2,3				ESM-2335080	ESM-2350100	ESM-2350125	ESM-2375160	ESM-2375200
2,4				ESM-2435080	ESM-2450100	ESM-2450125	ESM-2475160	ESM-2475200
2,5					ESM-2550100	ESM-2550125	ESM-2575160	ESM-2575200
2,6					ESM-2650100	ESM-2650125	ESM-2675160	ESM-2675200
2,7					ESM-2750100	ESM-2750125	ESM-2775160	ESM-2775200
2,8		ESM-2850100	ESM-2850125	ESM-2875160	ESM-2875200			
2,9		ESM-2950100	ESM-2950125	ESM-2975160	ESM-2975200			

Uwaga. Inne wymiary na zapytanie
Note. Other dimensions on request.