

带安全环凹槽的滚珠轴承保持架, 铝制

材料:

笼: 铝

球体: 钢, 硬化处理根据 DIN 5401

说明:

规格在直径 10 以上的滚珠轴承罩配有安全环
DIN 471 (206.72.) 的凹槽。


☞ 滚珠导向类型见D章开头。

☞ 轴承寿命和动态负荷指数见D章节的末尾部分。

l = 订购额定长度

l₁ = 生产长度

2060.61.

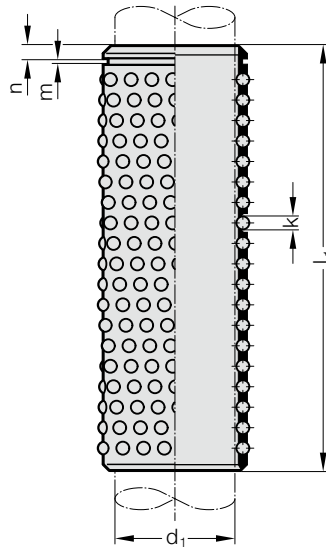

2060.61. 带安全环凹槽的滚珠轴承保持架, 铝制

d ₁	10 11 12	15	16	19	20	24 25	30 32	38 40	48 50	60 63	80
k	2	3	3	3	3	3	4	4	4	4	6
n	1.1	1.6	1.6	1.6	1.6	1.6	2.1	2.1	2.1	2.1	3
m	1.1	1.3	1.3	1.3	1.3	1.6	1.85	1.85	2.15	2.65	3.15
l/l ₁	总滚珠数量										
24 / 24			64		80						
28 / 28			80		100						
31 / 32				120	120	120					
40 / 39	176										
40 / 40						160	120				
45 / 44		144	144	180	180	180					
45 / 45							140	168			
50 / 50							160	192	224		
56 / 55							180	216			
56 / 56		192	192	240	240	240					
56 / 57	272										
63 / 64		224	224								
63 / 65								264	308		
71 / 70							240				
71 / 72		256	256	320	320	320					
80 / 80				360	360	360	280	336	392		
95 / 95							340	408	476	544	
95 / 96				440	440	440					
105 / 105							380	456	532	608	
120 / 119											540
120 / 120						560	440	528	616	704	
140 / 140							520	624	728	832	648
160 / 160							600	720	840	960	
160 / 161											756
180 / 180								816	952	1,088	
180 / 182											864
200 / 200								912	1,064	1,216	
200 / 203											972
240 / 238											1,152
240 / 240								1,104	1,288	1,472	

订购示例:

带安全环凹槽的滚珠轴承保持架, 铝制 = 2060.61.

导向装置直径 d₁ 38 mm = 038.

滚珠轴承保持架的订购额定长度 l 50 mm = 050

订购编号 = 2060.61. 038. 050