


模柄

模柄 DIN ISO 10242-1



211.11.

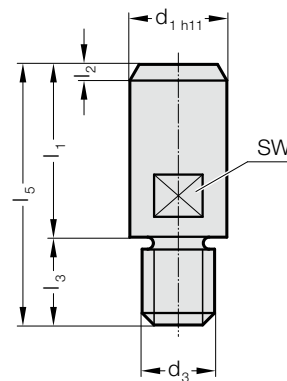


211.11. 模柄

| 订购编号 | d ₁ | d ₃ | l ₁ | l ₂ | l ₃ | l ₅ | SW* |
|---------------|----------------|----------------|----------------|----------------|----------------|----------------|-----|
| 211.11.20.016 | 20 | M16x1.5 | 40 | 3 | 18 | 58 | 17 |
| 211.11.25.016 | 25 | M16x1.5 | 45 | 4 | 23 | 68 | 21 |
| 211.11.25.020 | 25 | M20x1.5 | 45 | 4 | 23 | 68 | 21 |
| 211.11.32.020 | 32 | M20x1.5 | 56 | 4 | 23 | 79 | 27 |
| 211.11.32.024 | 32 | M24x1.5 | 56 | 4 | 23 | 79 | 27 |
| 211.11.40.024 | 40 | M24x1.5 | 70 | 5 | 23 | 93 | 36 |
| 211.11.40.030 | 40 | M30x2 | 70 | 5 | 23 | 93 | 36 |
| 211.11.50.030 | 50 | M30x2 | 80 | 6 | 28 | 108 | 41 |
| 211.11.65.042 | 65 | M42x3 | 100 | 8 | 28 | 128 | 55 |

* SW = 扳手开口度



211.12.

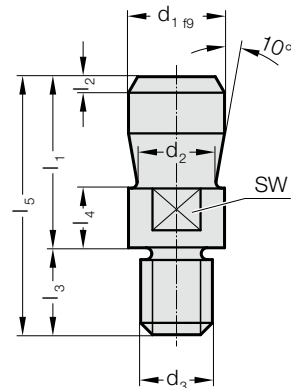

211.12. 模柄 DIN ISO 10242-1

| 订购编号 | d ₁ | d ₂ | d ₃ | l ₁ | l ₂ | l ₃ | l ₄ | l ₅ | SW* |
|---------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|-----|
| 211.12.20.016 | 20 | 15 | M16x1.5 | 40 | 2 | 18 | 12 | 58 | 17 |
| 211.12.25.016 | 25 | 20 | M16x1.5 | 45 | 2.5 | 23 | 16 | 68 | 21 |
| 211.12.25.020 | 25 | 20 | M20x1.5 | 45 | 2.5 | 23 | 16 | 68 | 21 |
| 211.12.32.020 | 32 | 25 | M20x1.5 | 56 | 3 | 23 | 16 | 79 | 27 |
| 211.12.32.024 | 32 | 25 | M24x1.5 | 56 | 3 | 23 | 16 | 79 | 27 |
| 211.12.40.024 | 40 | 32 | M24x1.5 | 70 | 4 | 23 | 26 | 93 | 36 |
| 211.12.40.027 | 40 | 32 | M27x2 | 70 | 4 | 23 | 26 | 93 | 36 |
| 211.12.40.030 | 40 | 32 | M30x2 | 70 | 4 | 23 | 26 | 93 | 36 |
| 211.12.50.030 | 50 | 42 | M30x2 | 80 | 5 | 28 | 26 | 108 | 41 |
| 211.12.65.042 | 65 | 53 | M42x3 | 100 | 8 | 28 | 26 | 128 | 55 |

* SW = 扳手开口度