


带肩六角螺母, DIN 6331
垫圈 DIN 6340



材料:
调质处理, 强度等级 10.9
结构:
车削和铣削处理
说明:
螺纹长度 $1.5 \times M$

2140.33.

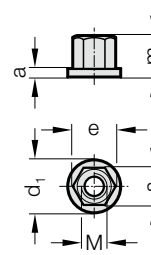


2140.33. 带肩六角螺母, DIN 6331

订购编号	M	a	d ₁	e	m	s
2140.33.08	M8	3.5	18	15	12	13
2140.33.10	M10	4	22	18.4	15	16
2140.33.12	M12	4	25	20.7	18	18
2140.33.14	M14	4.5	28	24.2	21	21
2140.33.16	M16	5	31	27.7	24	24
2140.33.18	M18	5	34	31.2	27	27
2140.33.20	M20	6	37	34.6	30	30
2140.33.22	M22	6	40	39.2	33	34
2140.33.24	M24	6	45	41.5	36	36
2140.33.30	M30	6	58	53.1	45	46



材料:
调质处理, 强度 1200-1400 N/mm²

2140.34.

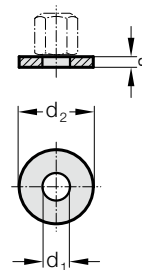

2140.34. 垫圈 DIN 6340

订购编号	M	d ₁	d ₂	s
2140.34.08	M8	8.4	23	4
2140.34.10	M10	10.5	28	4
2140.34.12	M12	13	35	5
2140.34.14	M14	15	40	5
2140.34.16	M16	17	45	6
2140.34.18	M18	19	45	6
2140.34.20	M20	21	50	6
2140.34.22	M22	23	50	8
2140.34.24	M24	25	60	8
2140.34.30	M30	31	68	10