


CANON DE PERÇAGE SANS COLLERETTE, DIN 179 FORME A

277.

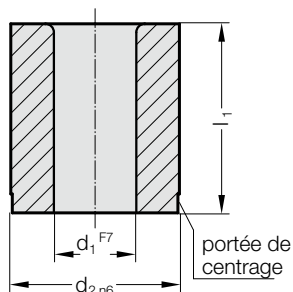

Matière :

Acier de cémentation
Dureté 740 ± 40 HV 10

Exécution :

Diamètres d_1 et d_2 rectifiés.

Autres dimensions et longueurs sur demande.

277. Canon de perçage sans collerette, DIN 179 Forme A

d_1	d_2	Gradation	l_1	6	8	9	10	12	16	20	25	28	30	36	45	56	67
0,9 - 1	3	0.1		●		●											
1,1 - 1,8	4	0.1		●		●											
1,9 - 2,6	5	0.1		●		●											
2,7 - 3,3	6	0.1			●			●	●								
3,4 - 4	7	0.1			●			●	●								
4,1 - 5	8	0.1			●			●	●								
5,1 - 6	10	0.1					●		●								
6,1 - 8	12	0.1					●		●	●							
8,1 - 10	15	0.1						●	●	●		●					
10,1 - 12	18	0.1						●	●	●	●						
12,1 - 15	22	0.1							●	●		●		●			
15,5 - 18	26	0.5							●			●		●			
18,5 - 22	30	0.5								●				●	●		
22,5 - 26	35	0.5								●				●	●		
26,5 - 30	42	0.5									●			●	●	●	
30,5 - 35	48	0.5									●				●	●	
35,5 - 42	55	0.5										●			●	●	●
42,5 - 48	62	0.5											●			●	●

Exemple de commande :

Canon de perçage sans collerette, DIN 179 Forme A	=	277.1.
Diamètre de guidage d_1	12.1 mm =	1210.
Longueur l_1	16 mm =	016
N° de commande	=	277.1. 1210.016