

# 精密扁钢和精密方钢, DIN 59350

2922.2842.



材料:

1.2842 / 90 MnCrV

冷锻模钢


结构:

厚度已精磨, 宽度已打磨或铣削, 长度已加工

说明:

● = 适用于 500 mm 和 1000 mm 长度

○ = 仅适用于 500 mm 长度

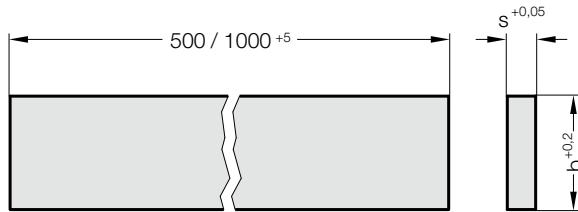

2922.2842. 精密扁钢和精密方钢, DIN 59350

s	1	2	3	4	5	6	8	10	12	15	16	20	25	30	40	50	60
b																	
4				○													
5					○												
6						●											
8							●										
10	○	●	●	●	●	●	●	●									
12	○	●	●	●	●	●	●	●	●								
15	○	●	●	●	●	●	●	●	●	●							
16											●						
20	○	●	●	●	●	●	●	●	●	●		●					
25	○	●	●	●	●	●	●	●	●	●		●	●				
30	○	●	●	●	●	●	●	●	●	●		●	●	●			
35	○	●	●	●	●	●	●	●	●	●		●	●	●			
40	○	●	●	●	●	●	●	●	●	●		●	●	●	●		
50	○	●	●	●	●	●	●	●	●	●		●	●	●	●	●	
60	○	●	●	●	●	●	●	●	●	●		●	●	●	●	●	●
70	○	●	●	●	●	●	●	●	●	●		●	●	●	●	●	●
80	○	●	●	●	●	●	●	●	●	●		●	●	●	●	●	●
100	○	●	●	●	●	●	●	●	●	●		●	●	●	●	●	●
120	○	●	●	●	●	●	●	●	●	●		●	●	●	●	●	●
125	○	●	●	●	●	●	●	●	●	●		●	●	●	●	●	●
150	○	●	●	●	●	●	●	●	●	●		●	●	●	●	●	●
160	○	●	●	●	●	●	●	●	●	●		●	●	●	●	●	●
180	○	●	●	●	●	●	●	●	●	●		●	●	●	●	●	●
200	○	●	●	●	●	●	●	●	●	●		●	●	●	●	●	●
250	○	●	●	●	●	●	●	●	●	●		●	●	●	●	●	●
300	○	●	●	●	●	●	●	●	●	●		●	●	●	●	●	●

订购示例:

精密扁钢和精密方钢, DIN 59350	=	2922.2842.
宽 B	50 mm =	050.
厚度 S	1 mm =	001.
长度 L	500 mm =	0500
订购编号	=	2922.2842. 050. 001. 0500