


符合DIN 59350带有加工余量的精密扁钢和精密方钢

材料:
1.2162 / 21 MnCr 5
渗碳钢
结构:
厚度已精磨, 宽度已打磨或铣削, 长度已加工

2923.2162.



我们为您提供
BÖHLER
原装质量

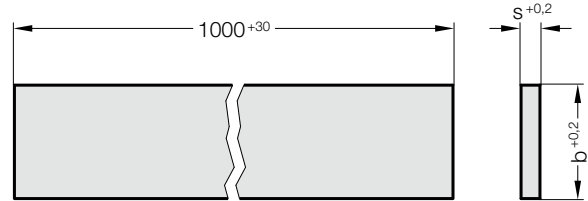

2923.2162. 符合DIN 59350带有加工余量的精密扁钢和精密方钢

s	8.2	10.4	12.4	15.4	20.4	25.4	30.4	40.4	50.4	60.4	80.4
b											
20.3	●	●	●	●							
20.4					●						
25.3	●	●	●	●	●						
25.4						●					
30.3	●	●	●	●	●	●					
30.4							●				
40.3	●	●	●	●	●	●	●				
40.4								●			
50.3	●	●	●	●	●	●	●	●			
50.4									●		
60.3	●	●	●	●	●	●	●	●	●		
60.4										●	
70.3	●	●	●	●	●	●	●	●	●	●	
80.3	●	●	●	●	●	●	●	●	●	●	●
80.4											●
100.3	●	●	●	●	●	●	●	●	●	●	●
150.3	●	●	●	●	●	●	●	●	●	●	●
200.3	●	●	●	●	●	●	●	●	●	●	●
250.3	●	●	●	●	●	●	●	●	●	●	●
300.3	●	●	●	●	●						

订购示例:

符合DIN 59350带有加工余量的精密扁钢和精密方钢	=	2923.2162.
宽 B	40.3 mm =	040.
厚度 S	8.2 mm =	008.
长度 L	1000 mm =	1000
订购编号	=	2923.2162. 040. 008. 1000