

符合DIN 59350带有加工余量的精密扁钢和精密方钢

材料:
1.2767 / X 45 NiCrMo 4
冷锻模钢


2923.2767.



我们为您提供
BÖHLER
原装质量

结构:
厚度已精磨, 宽度已打磨或铣削, 长度已加工

说明:
● = 适用于 500 mm 和 1000 mm 长度
○ = 仅适用于 500 mm 长度
■ = 仅适用于 1000 mm 长度

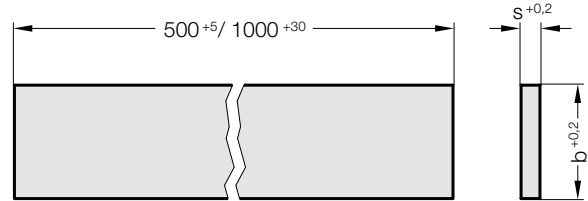

2923.2767. 符合DIN 59350带有加工余量的精密扁钢和精密方钢

s	4.2	5.2	6.2	8.2	10.4	12.4	15.4	16.4	20.4	25.4	30.4	32.4	40.4	50.4	60.4	80.4	100.4
10.3	○	○	○	○													
10.4					●												
12.4						●											
15.3	○	○	○	○	○	○											
15.4							○										
20.3	○	○	○	●	●	●	●	■									
20.4									●								
25.3	○	○	○	●	●	●	●	■	●								
25.4										●							
30.3	○	○	○	●	●	●	●		●	●							
30.4											●						
32.3								■	■	■							
40.3	○	○	○	●	●	●	●	■	●	●	●	■					
40.4													●				
50.3	○	○	○	●	●	●	●	■	●	●	●	■	●				
50.4														●			
60.3	○	○	○	●	●	●	●		●	●	●		●	●			
60.4															■		
63.3								■	■	■		■	■	■			
70.3				■	■	■			■	■		■	■	■			
80.3	○	○	○	●	●	●	●	■	●	●	●		●	●		■	
80.4																	■
100.3	○	○	○	●	●	●	●	■	●	●	●	■	●	●	■	■	
100.4																	■
125.3				●	●	●	●	■	●	●	●	■	●	●	■	■	■
150.3				■	■	■	■	■	■	■	■	■	■	■	■	■	■
200.3				■	■	■	■	■	■	■	■	■	■	■	■	■	■
250.3				■	■	■	■	■	■	■	■	■	■	■	■	■	■
300.3				■	■	■	■	■	■	■	■	■	■	■	■	■	■

订购示例:

符合DIN 59350带有加工余量的精密扁钢和精密方钢	=	2923.2767.
宽 B	25.3 mm =	025.
厚度 S	4.2 mm =	004.
长度 L	500 mm =	0500
订购编号	=	2923.2767. 025. 004. 0500