


VODÍČÍ SLOUPEK



3202.12.

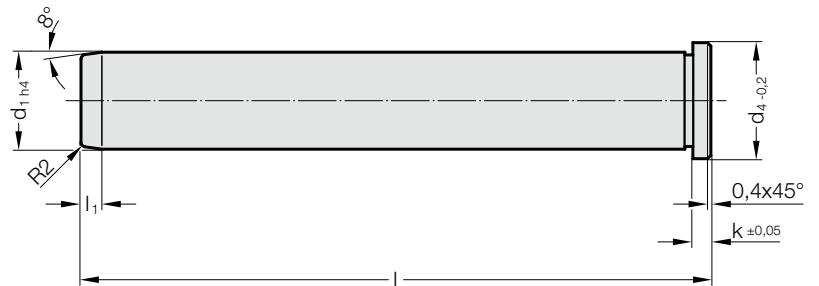


3202.12. Vodíčí sloupek

Objednací číslo	d_1	l	d_4	k	l_1
3202.12.012.080	12	80	16	4	4
3202.12.012.100	12	100	16	4	4
3202.12.012.120	12	120	16	4	4
3202.12.018.120	18	120	22	6	7
3202.12.018.140	18	140	22	6	7
3202.12.018.160	18	160	22	6	7
3202.12.030.160	30	160	36	6	7
3202.12.030.200	30	200	36	6	7
3202.12.030.240	30	240	36	6	7



3202.13.

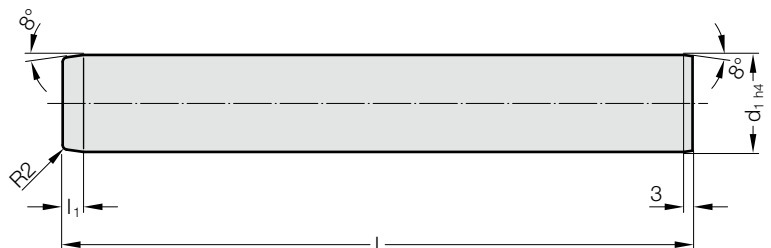

3202.13. Vodíčí sloupek

Objednací číslo	d_1	l	l_1
3202.13.012.100	12	100	3
3202.13.012.125	12	125	3
3202.13.018.125	18	125	6
3202.13.018.160	18	160	6
3202.13.030.160	30	160	6
3202.13.030.240	30	240	6