


## KALIP KOLONU



### 3202.12.

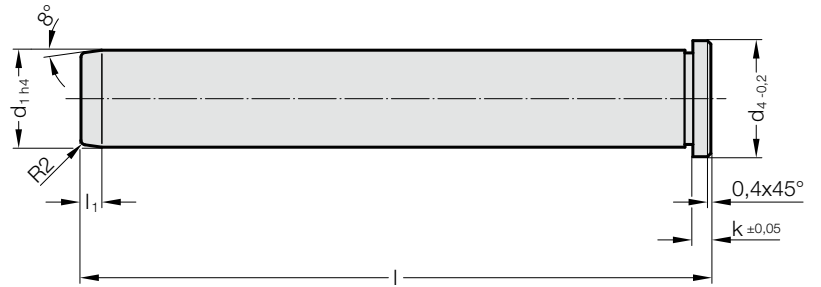


### 3202.12. Kalıp Kolonu

Sipariş No.	d <sub>1</sub>	l	d <sub>4</sub>	k	l <sub>1</sub>
3202.12.012.080	12	80	16	4	4
3202.12.012.100	12	100	16	4	4
3202.12.012.120	12	120	16	4	4
3202.12.018.120	18	120	22	6	7
3202.12.018.140	18	140	22	6	7
3202.12.018.160	18	160	22	6	7
3202.12.030.160	30	160	36	6	7
3202.12.030.200	30	200	36	6	7
3202.12.030.240	30	240	36	6	7



### 3202.13.

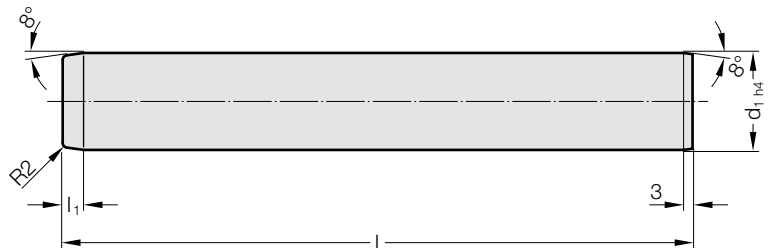

### 3202.13. Kalıp Kolonu

Sipariş No.	d <sub>1</sub>	l	l <sub>1</sub>
3202.13.012.100	12	100	3
3202.13.012.125	12	125	3
3202.13.018.125	18	125	6
3202.13.018.160	18	160	6
3202.13.030.160	30	160	6
3202.13.030.240	30	240	6