



Mehrbereichs-Blindniet OPTO®



Serie 10.612

Aluminium / Edelstahl



EN AW - 5052 [AlMg2,5]

- > Flachkopf
- > offen

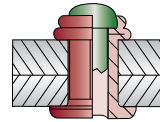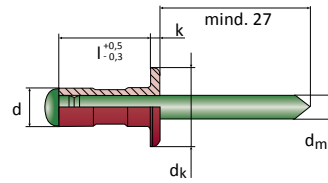

d	l +1		Nr.		
3,2	8,0	0,8 - 4,8	10.612.032.080	500	
	11,1	3,5 - 8,0	10.612.032.110	500	
d_k 6,4	d_m 1,8	k 1,0	3,3 mm		
4,0	9,5	1,2 - 6,4	10.612.040.095	500	
	12,7	4,0 - 9,5	10.612.040.127	500	
	16,9	6,4 - 12,7	10.612.040.169	500	
d_k 7,9	d_m 2,3	k 1,2	4,1 mm		

d	l +1		Nr.		
4,8	10,3	1,5 - 6,0	10.612.048.103	500	
	15,1	4,8 - 11,1	10.612.048.151	500	
	16,9	6,4 - 12,7	10.612.048.169	500	
	24,8	12,7 - 19,8	10.612.048.248	500	
d_k 9,8	d_m 2,8	k 1,5	4,9 mm		