



Mehrbereichs-Blindniet OPTO®



Serie 10.632/652/672

Aluminium / Edelstahl



EN AW - 5052 [AlMg2,5]

- > Großkopf
- > offen

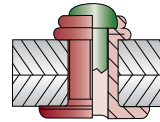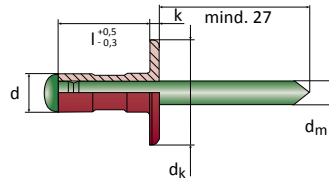

d	l +1		Nr.	
3,2	8,0	0,5 - 5,0	10.632.032.080	500
	11,0	4,0 - 7,9	10.632.032.110	500
d_k 9,5	d_m 1,8	k 1,2	3,3 mm 670 N	
4,0	9,5	1,2 - 6,4	10.652.040.095	500
	12,7	4,0 - 9,5	10.652.040.127	500
d_k 12,0	d_m 2,3	k 1,5	4,1 mm 980 N	

d	l +1		Nr.	
4,8	10,3	1,6 - 6,4	10.672.048.103	500
	16,9	6,4 - 12,7	10.672.048.169	500
	24,8	12,7 - 19,8	10.672.048.248	250
d_k 16,0	d_m 2,8	k 1,8	4,9 mm 1530 N	