



Mehrbereichs-Blindniet OPTO®

Serie 10.630/650/670





Aluminium / Stahl

Großkopf <
offen <



EN AW - 5052 [AlMg2,5]

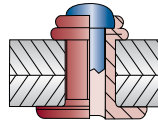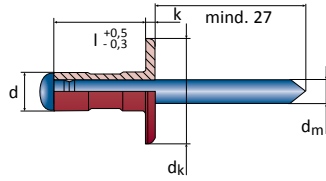

| d | l +1 | | Nr. | |
|---------------------------|--------------------------|--------------|------------------------|-----|
| 3,2 | 8,0 | 0,8 - 4,8 | 10.630.032.080 | 500 |
| | 11,0 | 4,0 - 7,9 | 10.630.032.110 | 500 |
| d_k 9,5 | d_m 1,8 | k 1,2 | 3,3 mm 720 N 1000 N | |
| 4,0 | 6,0 | 1,0 - 3,0 | 10.650.040.060 | 500 |
| | 9,5 | 1,2 - 6,4 | 10.650.040.095 | 500 |
| | 12,7 | 4,0 - 9,5 | 10.650.040.127 | 500 |
| | 16,9 | 6,4 - 12,7 | 10.650.040.169 | 500 |
| d_k 12,0 | d_m 2,3 | k 1,5 | 4,1 mm 1120 N 1650 N | |

NEU

NEU

| d | l +1 | | Nr. | |
|---------------------------|--------------------------|--------------|------------------------|-----|
| 4,8 | 10,3 | 1,6 - 6,4 | 10.670.048.103 | 500 |
| | 16,9 | 6,4 - 12,7 | 10.670.048.169 | 500 |
| | 24,8 | 12,7 - 19,8 | 10.670.048.248 | 500 |
| d_k 16,0 | d_m 2,8 | k 1,8 | 4,9 mm 1530 N 2300 N | |