



Mehrbereichs-Blindniet OPTO®

Serie 10.607



Stahl / Stahl

Flachkopf <
offen <

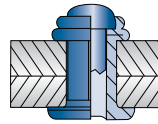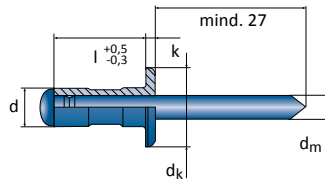

d	l +1		Nr.		
3,2	9,0	1,1 - 4,0	10.607.032.090	500	
	13,0	4,0 - 8,0	10.607.032.130	500	
d_k 7,2	d_m 2,1	k 0,9	3,3 mm	1500 N	1700 N
4,0	11,0	2,0 - 6,5	10.607.040.110	500	
d_k 8,1	d_m 2,7	k 1,2	4,1 mm	1950 N	2350 N

NEU

d	l +1		Nr.		
4,8	10,3	1,2 - 4,8	10.607.048.103	500	
	14,5	4,0 - 9,0	10.607.048.145	500	
	17,5	7,5 - 12,5	10.607.048.175	500	
d_k 9,8	d_m 2,9	k 1,8	4,9 mm	2700 N	3300 N
6,4	14,5	1,5 - 7,0	10.607.064.145	500	
	20,0	7,0 - 12,5	10.607.064.200	250	
	25,0	12,0 - 17,5	10.607.064.250	250	
d_k 12,7	d_m 3,8	k 2,2	6,5 mm	6500 N	4200 N

NEU

NEU

NEU

NEU

NEU