



# Standard Blindniet ALFO®

 

## Serien 10.742/762/772

**Aluminium / Edelstahl A2/A3**



EN AW - 5754 [AlMg3]

> Großkopf  
> offen

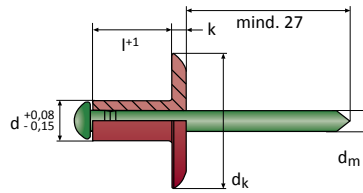

d	l +1		Nr.	
<b>5,0</b>	8,0	2,0 - 5,0	10.742.050.080	500
	10,0	4,0 - 6,5	10.742.050.100	500
	12,0	6,0 - 8,0	10.742.050.120	500
	14,0	7,5 - 10,0	10.742.050.140	500
	16,0	8,0 - 12,0	10.742.050.160	500
	18,0	11,5 - 13,5	10.742.050.180	500
	20,0	12,0 - 15,5	10.742.050.200	500
	25,0	15,0 - 20,5	10.742.050.250	500
	30,0	20,0 - 25,0	10.742.050.300	250

NEU

NEU

<b>d<sub>k</sub> 11,0 ±0,5</b>	<b>d<sub>m</sub> 2,7</b>	<b>k 1,5 +0,4</b>	5,1 mm	1650 N	2500 N
--------------------------------	--------------------------	-------------------	--------	--------	--------

<b>5,0</b>	10,0	4,0 - 6,5	10.772.050.100	500	NEU
	16,0	8,0 - 12,0	10.772.050.160	500	NEU
	20,0	12,0 - 15,5	10.772.050.200	250	NEU
	25,0	15,0 - 20,0	10.772.050.250	250	NEU
	33,0	20,0 - 28,0	10.772.050.330	100	NEU

<b>d<sub>k</sub> 16,0 ±0,3</b>	<b>d<sub>m</sub> 2,7</b>	<b>k 1,5 +0,4</b>	5,1 mm	1650 N	2500 N
--------------------------------	--------------------------	-------------------	--------	--------	--------

d	l +1		Nr.		
<b>5,0</b>	8,0	2,0 - 5,0	10.762.050.080	500	NEU
	10,0	4,0 - 6,5	10.762.050.100	500	
	12,0	6,0 - 8,0	10.762.050.120	500	
	14,0	7,5 - 10,0	10.762.050.140	500	
	16,0	9,5 - 12,0	10.762.050.160	500	
	18,0	11,5 - 13,5	10.762.050.180	500	
	20,0	12,0 - 15,5	10.762.050.200	500	
	25,0	15,0 - 20,5	10.762.050.250	250	
	30,0	20,0 - 25,0	10.762.050.300	250	NEU

<b>d<sub>k</sub> 14,0 ±0,3</b>	<b>d<sub>m</sub> 2,7</b>	<b>k 1,5 +0,4</b>	5,1 mm	1650 N	2500 N
--------------------------------	--------------------------	-------------------	--------	--------	--------