 



Langschaftbruch-Blindniet FERO®-BULB

Serie 10.790



Aluminium / Aluminium

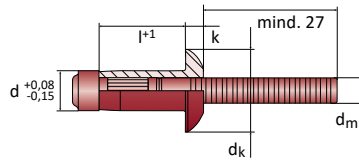

Flachkopf <
offen <

d	l +1		Nr.		
6,4	10,5	2,8 - 4,8	10.790.064.105	250	
d _k 13,5	d _m 4,2	k 3,0	6,6 mm	4200 N	3100 N
6,4	12,5	4,8 - 6,8	10.790.064.125	250	
d _k 13,5	d _m 4,2	k 3,0	6,6 mm	4500 N	3100 N
6,4	14,5	6,8 - 8,8	10.790.064.145	250	
d _k 13,5	d _m 4,2	k 3,0	6,6 mm	4600 N	3100 N

d	l +1		Nr.		
6,4	16,5	8,8 - 10,8	10.790.064.165	250	
d _k 13,5	d _m 4,2	k 3,0	6,6 mm	5000 N	3100 N
6,4	18,5	10,8 - 12,8	10.790.064.185	250	
d _k 13,5	d _m 4,2	k 3,0	6,6 mm	5400 N	3100 N
6,4	20,5	12,8 - 14,8	10.790.064.205	250	
d _k 13,5	d _m 4,2	k 3,0	6,6 mm	5600 N	3100 N