



For Series:

Chainfix Clip for C-profile:

For all KMA mounting brackets with C-profile-option!

Clip for C-profile
Part No. CFC-XX-C**Chainfix clip - Modular snap-on for the C-profile**

Available for all igus® E-ChainSystems with C-profiles. **Characteristic features:**

- Series of clamps and bottom parts made of plastic for cable diameters ranging from 4 mm to 24 mm
- Quick assembly without any tools
- 2 and 3 layers on top of one another possible
- Each layer can be detached and changed later on
- High tensile forces in case of single-layer installation, decreasing with the number of layers

ø Conduit [mm]	Part No. clamps	Part No. bottom part	Dim. A [mm]	Dim. B [mm]	Dim. C [mm]
04 - 08 mm	CFC-08-M	CFC-08-C	13,0	14,5	30
08 - 12 mm	CFC-12-M	CFC-12-C	24,0	23,7	36
12 - 16 mm	CFC-16-M	CFC-16-C	32,1	32,4	42
16 - 20 mm	CFC-20-M	CFC-20-C	39,1	43,2	45
20 - 24 mm	CFC-24-M	CFC-24-C	50,0	54,0	50



E4

- E4.56/H4.56/R4.56
- E4.80/H4.80/R4.80
- 1640
- 840
- 640
- 14040/14140
- 14550/14650
- 15050/15150

E6

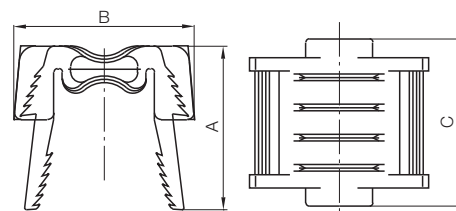
- E6.80L
- E6.80

Modular snap-on for crossbars

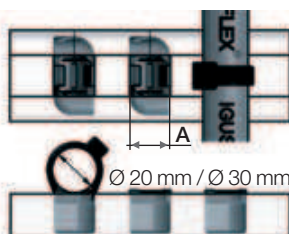
Available for all igus® E-ChainSystems with crossbar serie **Part. No. 450.XX**. **Characteristic features:**

- Series of clamps and bottom parts made of plastic for cable diameters ranging from 8 mm to 12 mm
- Quick assembly without any tools
- 2 and 3 layers on top of one another possible
- Each layer can be detached and changed later on
- High tensile forces in case of single-layer installation, decreasing with the number of layers

ø Conduit [mm]	Part No. clamps	Part No. crossbars	Dim. A [mm]	Dim. B [mm]	Dim. C [mm]
08 - 12 mm	CFC-12-M	CFC-12-B	24,0	23,7	36

Clip for crossbars
Part No. CFC-XX-BPhone +49- (0) 22 03-96 49-800
Fax +49- (0) 22 03-96 49-222igus® GmbH
51147 CologneInternet: www.igus.eu
E-mail: info@igus.de

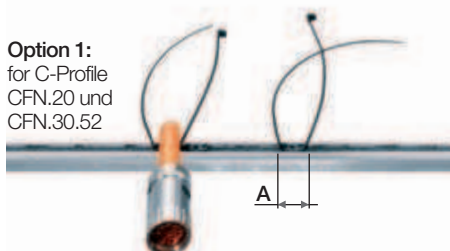
5.536

**Chainfix nugget - for top hat rail and C-profile**

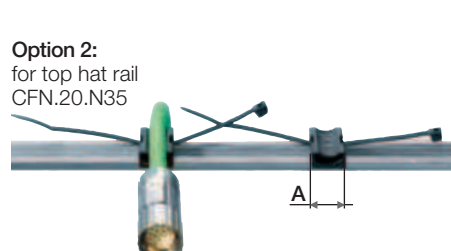
- **Option 1:** completely simple and universal cable fixation, for diameter with Ø 20 mm and Ø 30 mm
- **Option 2:** Fastening through clipping onto standard top hat rail
- **Characteristic features:**
- The smart helper for electricians in the machine building industry
- Accessory for all KMA with integrated C-profile
- Strain relief for top hat rail
- Easy to assemble, without any screws and tools
- Adjustable to every E-Chain® filling
- Very small space requirement
- Easy strain relief due to fixation with pre-harnessed cable strap

For fixation	Part No. Nugget	ø Conduit max. [mm]	Dim. A [mm]
C-Profile 92.42.../92.42...E	CFN.20	20	10,8
C-Profile 92.52.../92.52...E	CFN.30.52	30	16,4
Top hat rail 35	CFN.20.N35	20	20,0

Option 1:
for C-Profile
CFN.20 und
CFN.30.52



Option 2:
for top hat rail
CFN.20.N35

Available from stock. **Delivery in 24h or today!** (Delivery time means time until shipping of goods)