 



Enddeckel, oval – EDO




Höhe h mm	Breite b mm	Einsteck- tiefe l_p mm	Ober- fläche A_i m ²	Gewicht kg	Verpackungs- einheit VPE Stck/VPE
50	195	45	0,033	0,16	10
	260	45	0,044	0,20	10
80	320	65	0,078	0,43	9
100	350	65	0,095	0,51	6

Anschlussstutzen, oval, 90° – ASTO

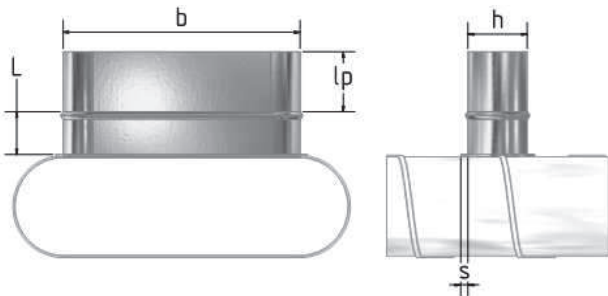

Höhe h mm	Breite b mm	Einsteck- tiefe l_p mm	Einbaulänge L mm	Bord- Breite S mm	Ober- fläche A_i m ²	Gewicht kg	Verpackungs- einheit VPE Stck/VPE
50	195	40	40	10	0,040	0,20	10
	260	40	40	10	0,052	0,26	10
80	320	80	50	15	0,107	0,64	4
100	350	80	50	15	0,119	0,70	10

Anschlussstutzen, symmetrisch, oval – ASTSO

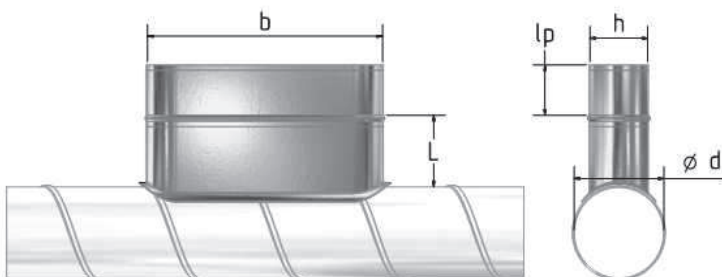

Durch- messer d mm	Höhe h mm	Breite b mm	Einsteck- tiefe l_p mm	Einbaulänge L mm	Ober- fläche A_i m ²	Gewicht kg	Verpackungs- einheit VPE Stck/VPE
80-500	50	195	40	15	0,036	0,17	10
		260	40	15	0,047	0,22	8
	80	320	60	90	0,136	0,77	4
100-500	100	350	60	90	0,155	0,86	4