

BARRA TEMPRATA E RETTIFICATA (ADATTA PER FILETTATURE INTERNE)


GROUND BAR HARDENED (SUITABLE FOR INTERNAL THREADS)

STAB, GESCHLIFFEN UND GEHÄRTET (FÜR INNENGEWINDE)

BTR-1


Acciaio: UNI C 53 (W Nr 1.1213)
Steel: UNI C 53 (W Nr 1.1213)
Stahl: UNI C 53 (W Nr 1.1213)

Durezza: Superficie HRC 61-64
Hardness: Surface HRC 61-64
Härte: Oberfläche HRC 61-64

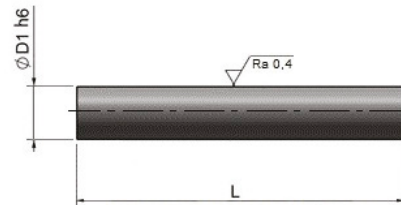

D1	L= 1000
8	-
10	-
12	-
14	-
16	-
18	-
20	-
24	-
25	-
30	-
32	-
40	-
50	-
60	-

Possibile utilizzo - Possible application - Möglicher Einsatz

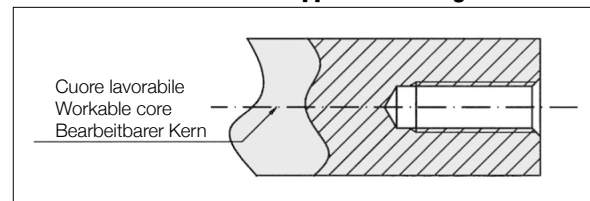

Esempio di ordinativo: D1xL **Order example:** D1xL **Bestellbeispiel:** D1xL

Altre lunghezze disponibili a richiesta - Other lengths supplied on request - Andere Längen auf Anfrage verfügbar