


MOLLA IN POLIURETANO FORATA / NON FORATA
DRILLED / NOT DRILLED POLYURETHANE SPRING
POLYURETHAN-FEDER, GELOCHT / NICHT GELOCHT

EMP-1

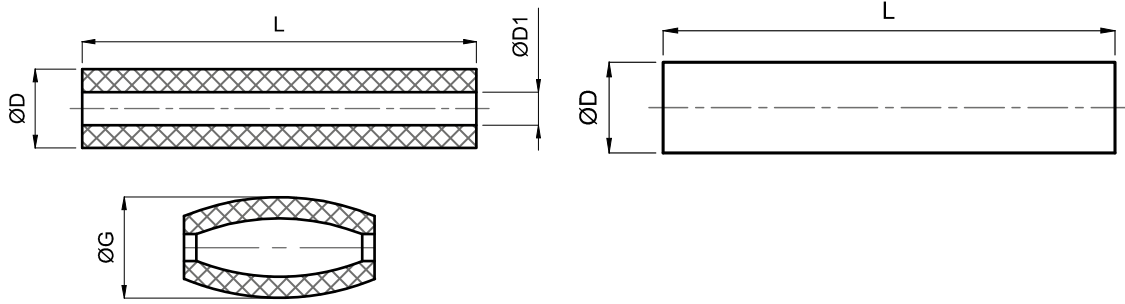

	COD. 80 (verde / green / grün)	COD. 90 (rosso / red / red)	COD. 95 (giallo / yellow / gelb)
Sigla Courbhane:			
Courbhane Mark:	80	90	95
Courbhane Code:			
Durezza Shore:			
Shore Hardness:	80	90	95
Shore Härte:			
Schiacciamento Massimo*:			
Maximum Crushing*:	33%	25%	20%
Maximale Quetschung*:			

*molla forata / drilled spring / feder gelocht

- D=** Diametro esterno - outside diameter - Außendurchmesser
- D1=** Diametro del foro - hole diameter - Lochdurchmesser
- L=** Altezza libera - free height - freie Höhe
- G=** Diametro massimo di gonfiamento
Maximum swelling diameter
Maximaler Schwelldurchmesser

D	D1	L	G. MAX		
			COD. 80	COD. 90	COD. 95
16	6,5	500	21	20	19
20	8,5	500	27	26	25
25	10,5	500	34	32	30
32	13,5	500	44	40	39
40	13,5	500	55	50	49
50	17	500	67	63	60
63	17	500	82	80	76
80	21	500	106	104	100
100	21	500	128	125	122
125	27	500	156	150	148

Esempio di ordinativo: D x Cod. x Forata/Non Forata

Order example: D x Cod.x Drilled/Not Drilled **Bestellbeispiel:** D x Cod. x Gelocht/Nicht Gelocht