


门部件 插销

选型指南

举例	型号	
	Code	L
标准	DK17S 50	

■ 插销1



Code	材质
DK17S	SUS304

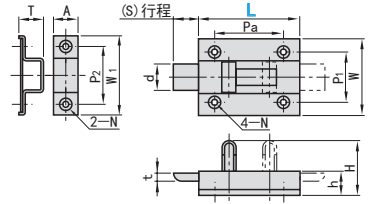

型号		Pa	P1	P2	W	W1	d	S	A	T	t	H	h	N		重量(g)
Code	L													通孔	镗锥孔	
DK17S	50	34	25	28	38	38	13	12.5	12	12.5	4	27	12	3.5	7	57
	65	47	31	32	45	45	15	15	15	13.5	5	28	12.5	5	9	99

■ 插销2

Code	材质
DK16S	SUS304

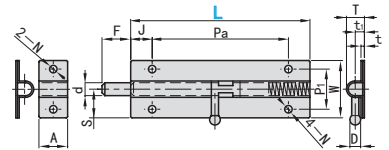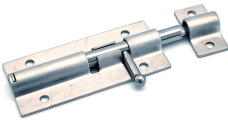

型号		W	Pa	P1	D	d	T	t	t1	A	S	F	J	N	重量(g)
Code	L														
DK16S	90	40	60	28	7.5	9	12	2.4	5.7	20	20	20	15	5	127
	125	40	95	28	7.5	9	12	2.4	5.7	20	20	20	15	5.2	166
	180	60	140	40	10	13	16	3	8	25	30	25	20	6.2	450