

蝶形铰链 带阻尼任意角度定位型

code
5天发货


选型指南

举例	型号
Code	No.
标准	HY607B 12




Code	材质	表面处理/颜色
HY60ZB	ZDC	黑色亚光

No. =11~13

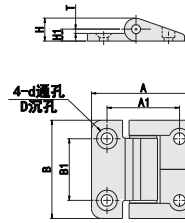

No. =31~38

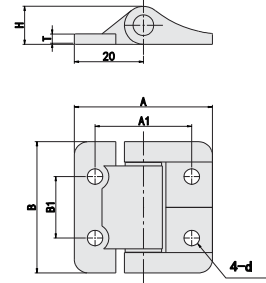

型号		A	B	A ₁	B ₁	H	H ₁	T	D	d	对称扭矩 N·m	负载 (kg)	参考重量 (kg/pcs)
Code	No.												
HY60ZB	11	57	50.8	34	34	12.7	6.3	4.5	12	5.2	1.8	15	0.11
	12										2.3		
	13										3.4		
	31	40	38	28	17.8	11	-	3	-	4.5	2.8	10	0.04
	32										1.4		
	33										1.8		
	34										2.3		
	38										0.9		

支柱

支柱座

支柱
固定夹

触摸屏
支架

支脚

脚轮

拉手

手柄·
旋钮

手轮

铰链

门部件