

旋钮 螺纹型\直纹型\五角型


code
5天发货

选型指南

举例	型号 Code M	-	L	型号 Code M	-	型号 Code M	-	D	-	L
标准	KRC	3	10	KRCN	8	XNKB	5	25	20	

内螺纹型	外螺纹型	材质	表面处理
KRCN	KRC	S45C	发黑
KRCNS	KRCS	SUS303	-


■ 旋钮-螺纹型

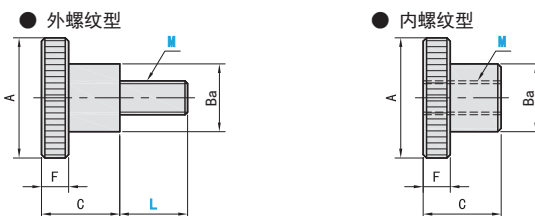


型号		L	A	Ba	C	F	型号		A	Ba	C	F
Code	M						Code	M				
外螺纹 KRC	3	6 10 12 16	12	6	7.5	2.5	内螺纹 KRCN	3	12	6	7.5	2.5
	4	5 8 10 12 16 20 25	16	8	9.5	3.5		4	16	8	9.5	3.5
	5	6 8 10 12 16 20 25 30	20	10	11.5	4		5	20	10	11.5	4
	6	8 10 12 16 20 25 30 35	24	12	15	5		6	24	12	15	5
	8	12 16 20 25 30 35 40	30	16	18	6		8	30	16	18	6
10	20 25 30 35 40	36	20	23	8	10	36	20	23	8		
							12	40	22	25	10	

型号		L	A	Ba	C	F	型号		A	Ba	C	F
Code	M						Code	M				
外螺纹 KRCS	4	8 10 12 16	16	8	9.5	3.5	内螺纹 KRCNS	4	16	8	9.5	3.5
	5	10 12 16 20 25	20	10	11.5	4		5	20	10	11.5	4
	6	12 16 20 25 30	24	12	15	5		6	24	12	15	5
	8	16 20 25 30	30	16	18	6		8	30	16	18	6


■ 旋钮-直纹型

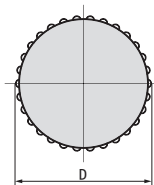

XNBB (内螺纹)

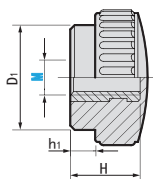


XNBC (外螺纹)

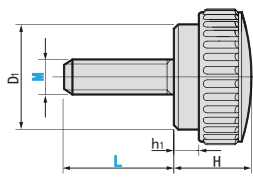


◆材质: 胶木

型号		L (仅外螺纹型可选择)	D	H	h1	D1
Code	M					
XNBB (内螺纹) XNBC (外螺纹)	4	10 15 20	16	11	3	12
	5	10 15 20 25	20	12	4	14
	6	10 15 20 30	25	17	5	17
	8	15 20 25 30	32	21	6	23
10	25 30 40	40	23	7	31	


■ 旋钮-塑料五角型 (外螺纹)

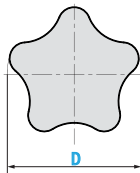

XNKB (内螺纹)

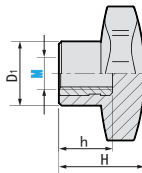

XNKC (外螺纹)

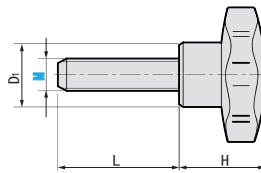

◆材质: 胶木

型号		D	L (仅外螺纹型可选择)	H	D1	h
Code	M					
XNKB (内螺纹) XNKC (外螺纹)	5	25	10 15 20 25 30 35 40	18	15	10
	6	25	10 15 20 25 30 35 40	18	15	12
	6	32	20 25 30 35 40 45	23	19	12
	8	40	15 20 25 30 35 40 45 50	26	21	16
	10	50	15 20 25 30 35 40 45 50 55	32	27	20
	12	63	20 25 30 35 40 45 50 55 60 65	37	31	25

框架部品及配件

支柱

支柱座

支柱固定夹

触摸屏支架

支脚

脚轮

拉手

手柄·旋钮

手轮

铰链

门部件