



拉手 带橡胶拉手\外螺纹圆形拉手

code  
5天发货

选型指南

举例	型号		L	H	垫圈选择	型号		L
	Code	D				Code	D	
标准	LS16S	10	120	50	S	LS30S	10	80
	LS17S	10	125	50				

带橡胶拉手

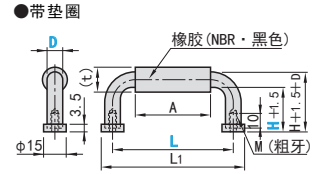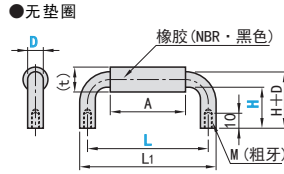

Code		材质	表面处理
无垫圈	带垫圈		
LS16S	LS17S	SUS304+橡胶	抛光
LS16C	LS17C	SUM22L或SUM24L+橡胶	镀铬

支柱

支柱座

支柱  
固定夹

触摸屏  
支架

支脚

脚轮

拉手

手柄 ·  
旋钮

手轮

铰链

门部件

型号		L	H	垫圈选择 (仅带垫圈型)	L1	M	A	(t)	容许负载 (N)
Code	D								
无垫圈 LS16S LS16C 带垫圈 LS17S LS17C	10	80	27	G (SUM22L) 镀铬	90	5	50	11.5	2500
			50						
		100	27						
			50						
		110	27						
			50						
		120	27						
			50						
	125	27							
		50							
	160	27	B SUM22L (静电喷涂 · 黑色)	170	5	130	13.5		
		50							
	200	27							
		50							
250	27								
	50								
12	150	40	S (SUS304)	162	8	120	13.5		
		75							
	188	40							
		75							
	238	40							
		75							
288	40								
	75								