 


暗式拉手 快速安装型

code
5天发货


选型指南

举例	型号	型号
	Code A	Code No.
标准	LS56P 94	LS57P 103.5




Code	类型	材质	表面处理/颜色
LS56P	B型	PA	黑色
LS57P	D型	ABS	
LS58PB	-	ABS+PC	象牙色
LS58PW		TPE	黑色


LS56P

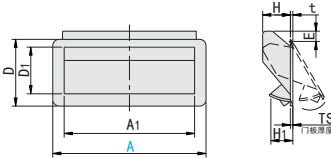


LS57P

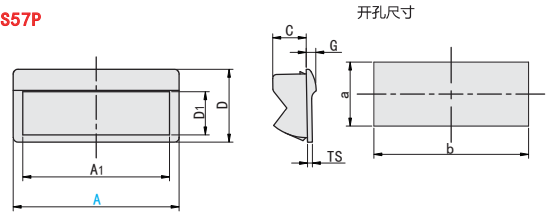

LS58PB
LS58PW

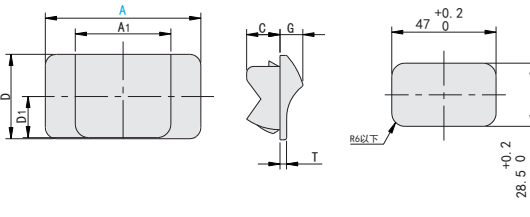

LS59P

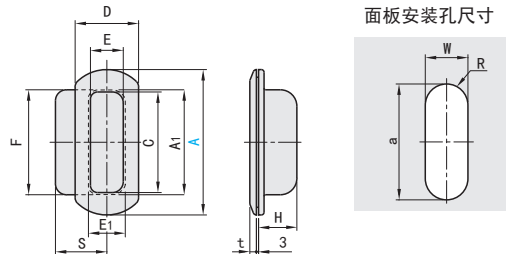

型号		A ₁	D	D ₁	H	H ₁	t	E	参考重量 (kg/pcs)
Code	A								
LS56P	94	80	41	28.7	17	13.5	1.5	5	0.02
	110	94	57	40.3	26	18.65	2	10	0.04

型号		TS 门板厚度	开孔尺寸	
Code	A		a	b
LS56P	94	0.75~0.79	34.8	85
		0.8~1.4	35	
	110	1.5~2.2	36	100
		1.5~2	49.6	
	2.1~3.2	50.3		
	3.3~3.5	51		

型号		A	A ₁	D	D ₁	C	G	T
Code	No.							
LS57P	103.5	103.5	91.5	45.5	27	21	6	3

型号		TS 门板厚度	开孔尺寸	
Code	No.		a	b
LS57P	103.5	1~1.2	40	96.5
		1.5~1.7	40.5	
		2~2.2	41.3	

型号		A ₁	D	D ₁	C	G	T	b	a			参考重量 (kg/pcs)
Code	A								适用板厚0.8~1.2	适用板厚1.4~1.8	适用板厚2~2.4	
LS58PB	70	43	38	18.5	15	10.5	3	47	28.5	29.3	30	0.02
	90	63	44	22.9				67	34.5	35.3	36	0.02
LS58PW	110	83	50	26.8				11.5	3.5	89	40.5	41.3
	140	109	64	37.8			115	54.5	55.3	56	0.05	

型号		A ₁	D	C	E	E ₁	F	H	S	t	开孔尺寸			参考重量 (kg/pcs)
Code	A										W	a	R	
LS59P	62	53	34	40	18	23	44	18	29	4	24	54	11.5	0.03
	92	83	42	62	22	27	66	32	42	5	28	84	13.5	0.05
	133	119	58	92	30	39	96	35	47	6	40	120	19.5	0.11