

Drawer for keyboard and mouse

with mousepad support

For installation in:


- VIP 6000 Command Panel¹⁾ (installation depth **4**, **6** or **8**, see page 217, 3.1)
- Any sufficiently large surface (e.g. door, side panel).

Suitable for accommodating

- Keyboards up to a maximum of 460 x 42 x 170 mm.
- Standard mouse and mousepad

Design:

- Drawer and enclosure
 - with side pull-out mousepad support and tray
- Front panel
 - with 3 mm double-bit lock insert
 - folds out as a wrist support

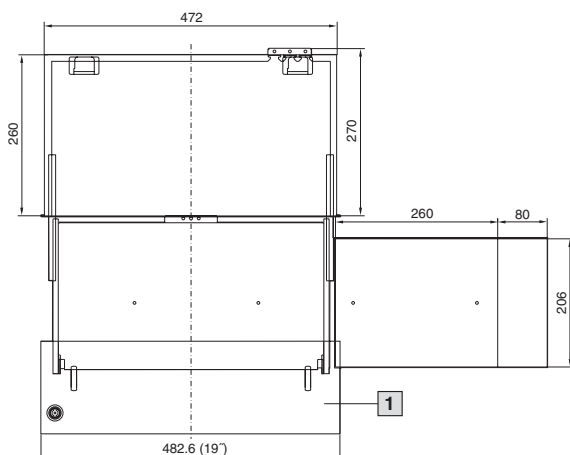

1 Front trim panel

Width mm	Height	Depth mm	Model No. CP
482.6 (19")	3.5 U	261	6003.000

Material:

Keyboard and drawer: Sheet steel
Front panel: Aluminium, natural-anodised.

Supply includes:

Assembly parts for installation in VIP 6000 Command Panel.



Also required:


¹⁾ For sub-division of the operating front, a cross member (see page 218, version 3.2) is required. The end trim (see page 219, version 3.4) must be selected at the same time.



Accessories:

Standard double-bit lock insert may be exchanged for 27 mm lock inserts, version A, see page 956.

Mounting cut-out for installation in surfaces

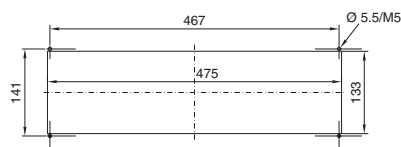

Keyboard drawer 1 U

for 482.6 mm (19") attachment level

This space-saving keyboard drawer is screw-fastened to the front and rear 482.6 mm (19") attachment level.

The installation spacing is infinitely adjustable from 460 – 800 mm.

It is fully extendible, lockable, with strain relief and hinged cable support.

The drawer is suitable to accommodate 482.6 mm (19") keyboards.

Interior dimensions:

W x H x D approx. 420 x 40 x 220 mm

Material:

Sheet steel

Colour:

RAL 7035

Supply includes:

Assembly parts, excluding keyboard.



Note:

Monitor/keyboard unit, 1 U, see page 840.

Distance between levels mm	Model No. DK
460 – 800	7281.200



Accessories:

482.6 mm (19") long-stroke keyboard with numeric keypad and touchpad, connection cable (approx. 1.15 m) and PS/2 connector, colour RAL 7035.

W x H x D mm	Keyboard layout	Model No. DK
415 x 37 x 193	German	9004.400
	US English	9004.402
	French	9004.403
	Spanish	9004.404
	Finnish	9004.406
	Swedish	9004.407