

Compact enclosures AE



System accessories Page 507 AE sheet steel Page 46 Hygienic Design Page 171

Material:

- Enclosure: Stainless steel
- Door: Stainless steel, all-round foamed-in PU seal
- Mounting plate: Sheet steel

Surface finish:

- Enclosure and door: Brushed, grain 240
- Mounting plate: Zinc-plated

Supply includes:


- Enclosure with door(s)
 - Mounting plate
- Please note the product-specific scope of supply.

Approvals:

- UL
- CSA
- TÜV
- Germanischer Lloyd
- Russian Maritime Register of Shipping
- Lloyds Register of Shipping
- Bureau Veritas
- VDE

Technical details:

Available on the Internet

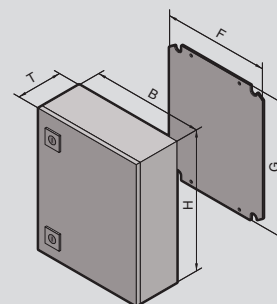

Stainless steel

Width (B) mm	Packs of	200	200	200	300	380	380	Page
Height (H) mm		300	300	300	300	300	300	
Depth (T) mm		120	155	155	210	155	210	
Mounting plate width (F) mm		162	162	162	254	344	334	
Mounting plate height (G) mm		275	275	275	275	275	275	
Material	Stainless steel 1.4301 (AISI 304)	■	-	■	■	■	■	
	Stainless steel 1.4404 (AISI 316L)	-	■	-	-	-	-	
Material of lock	Die-cast zinc, nickel-plated	■	-	■	■	■	■	
	Stainless steel 1.4404 (AISI 316L)	-	■	-	-	-	-	
Model No.	1 pc(s).	1001.600	1002.500	1002.600	1003.600	1004.600	1011.600	
Weight kg		3.6	4.1	4.1	6.9	7.4	8.4	
Protection category IP to IEC 60 529		IP 66	IP 66	IP 66	IP 66	IP 66	IP 66	
Protection category NEMA		NEMA 4X	NEMA 4X	NEMA 4X	NEMA 4X	NEMA 4X	NEMA 4X	
Product-specific scope of supply								
Door(s)		1	1	1	1	1	1	
Cam lock		1	1	1	1	1	2	
3-point lock system		-	-	-	-	-	-	
Accessories								
Rails for interior installation	4 pc(s).	-	-	-	2383.210	-	2383.210	605
Rain canopies, stainless steel	1 pc(s).	-	2470.000	2470.000	2361.000	2471.000	2472.000	580
Wall mounting bracket	4 pc(s).	2433.000	2433.500	2433.000	2433.000	2433.000	2433.000	587
Wall angle	4 pc(s).	2583.010	2583.010	2583.010	2583.010	2583.010	2583.010	588
Pole clamp	1 set(s)	2584.000	2584.000	2584.000	2584.000	2584.000	2584.000	589
Cam locks	1 pc(s).	2304.000	2304.000	2304.000	2304.000	2304.000	2304.000	570
Cam lock HD	1 pc(s).	2304.010	2304.010	2304.010	2304.010	2304.010	2304.010	172
Lock systems		from page	from page	from page	from page	from page	from page	563

Compact enclosures AE

Stainless steel

Width (B) mm	Packs of	300	300	380	380	600	400	Page
Height (H) mm		380	380	380	380	380	500	
Depth (T) mm		210	210	210	210	210	210	
Mounting plate width (F) mm		275	275	334	334	549	354	
Mounting plate height (G) mm		334	334	355	355	355	475	
Material	Stainless steel 1.4301 (AISI 304)	–	■	–	■	■	■	
	Stainless steel 1.4404 (AISI 316L)	■	–	■	–	–	–	
Material of lock	Die-cast zinc, nickel-plated	–	■	–	■	■	■	
	Stainless steel 1.4404 (AISI 316L)	■	–	■	–	–	–	
Model No.	1 pc(s).	1005.500	1005.600	1006.500	1006.600	1009.600	1015.600	
Weight kg		8.4	8.4	9.8	9.8	14.6	12.9	
Protection category IP to IEC 60 529		IP 66	IP 66	IP 66	IP 66	IP 66	IP 66	
Protection category NEMA		NEMA 4X	NEMA 4X	NEMA 4X	NEMA 4X	NEMA 4X	NEMA 4X	
Product-specific scope of supply								
Door(s)		1	1	1	1	1	1	
Cam lock		1	1	1	1	1	2	
3-point lock system		–	–	–	–	–	–	
Accessories								
Rails for interior installation	4 pc(s).	2383.210	2383.210	2383.210	2383.210	2383.210	2383.210	605
Rain canopies, stainless steel	1 pc(s).	2361.000	2361.000	2472.000	2472.000	2473.000	–	580
Wall mounting bracket	4 pc(s).	2433.500	2433.000	2433.500	2433.000	2433.000	2433.000	587
Wall angle	4 pc(s).	2583.010	2583.010	2583.010	2583.010	2583.010	2583.010	588
Pole clamp	1 set(s)	2584.000	2584.000	2584.000	2584.000	2584.000	2584.000	589
Cam locks	1 pc(s).	2304.000	2304.000	2304.000	2304.000	2304.000	2304.000	570
Cam lock HD	1 pc(s).	2304.010	2304.010	2304.010	2304.010	2304.010	2304.010	172
Lock systems		from page	from page	from page	from page	from page	from page	563

Stainless steel

Width (B) mm	Packs of	500	500	380	600	600	600	Page
Height (H) mm		500	500	600	600	600	760	
Depth (T) mm		210	300	210	210	210	210	
Mounting plate width (F) mm		449	449	334	549	549	549	
Mounting plate height (G) mm		470	470	570	570	570	730	
Material	Stainless steel 1.4301 (AISI 304)	■	■	■	–	■	■	
	Stainless steel 1.4404 (AISI 316L)	–	–	–	■	–	–	
Material of lock	Die-cast zinc, nickel-plated	■	■	■	–	■	■	
	Stainless steel 1.4404 (AISI 316L)	–	–	–	■	–	–	
Model No.	1 pc(s).	1007.600	1013.600	1008.600	1010.500	1010.600	1012.600	
Weight kg		15.7	18.4	15.1	23.5	23.5	30.2	
Protection category IP to IEC 60 529		IP 66	IP 66	IP 66	IP 66	IP 66	IP 66	
Protection category NEMA		NEMA 4X	NEMA 4X	NEMA 4X	NEMA 4X	NEMA 4X	NEMA 4X	
Product-specific scope of supply								
Door(s)		1	1	1	1	1	1	
Cam lock		2	2	2	2	2	2	
3-point lock system		–	–	–	–	–	–	
Accessories								
Rails for interior installation	4 pc(s).	2383.210	2383.300	2383.210	2383.210	2383.210	2383.210	605
Rain canopies, stainless steel	1 pc(s).	2362.000	–	2472.000	2473.000	2473.000	2473.000	580
Wall mounting bracket	4 pc(s).	2433.000	2433.000	2433.000	2433.500	2433.000	2433.000	587
Wall angle	4 pc(s).	2583.010	2583.010	2583.010	2583.010	2583.010	2583.010	588
Pole clamp	1 set(s)	2584.000	2584.000	2584.000	2584.000	2584.000	2584.000	589
Cam locks	1 pc(s).	2304.000	2304.000	2304.000	2304.000	2304.000	2304.000	570
Cam lock HD	1 pc(s).	2304.010	2304.010	2304.010	2304.010	2304.010	2304.010	172
Lock systems		from page	from page	from page	from page	from page	from page	563

Compact enclosures AE

Stainless steel

Width (B) mm	Packs of	760	800	1000	800	1000	1000	Page
Height (H) mm		760	1000	1000	1200	1200	1200	
Depth (T) mm		300	300	300	300	300	300	
Mounting plate width (F) mm		704	739	939	740	940	940	
Mounting plate height (G) mm		730	955	955	1155	1155	1155	
Material	Stainless steel 1.4301 (AISI 304)	■	■	■	■	–	■	
	Stainless steel 1.4404 (AISI 316L)	–	–	–	–	■	–	
Material of lock	Die-cast zinc, nickel-plated	■	■	■	–	–	–	
	Stainless steel 1.4301 (AISI 304)	–	–	–	■	■	■	
Model No.	1 pc(s).	1014.600	1016.600	1018.600	1017.600	1019.500	1019.600	
Weight kg		42.5	52.9	71.0	61.5	76.0	76.0	
Protection category IP to IEC 60 529		IP 66	IP 66	IP 55	IP 66	IP 55	IP 55	
Protection category NEMA		NEMA 4X	NEMA 4X	NEMA 12	NEMA 4X	NEMA 12	NEMA 12	
Product-specific scope of supply								
Door(s)		1	1	2	1	2	2	
Cam lock		2	2	2	–	–	–	
3-point lock system		–	–	–	■	■	■	
Accessories								
Rails for interior installation	4 pc(s).	2383.300	2383.300	2383.300	2383.300	2383.300	2383.300	605
Rain canopies, stainless steel	1 pc(s).	2474.000	2475.000	2363.000	2475.000	2363.000	2363.000	580
Wall mounting bracket	4 pc(s).	2433.000	2433.000	2433.000	2433.000	2433.500	2433.000	587
Wall angle	4 pc(s).	2583.010	2583.010	2583.010	2583.010	2583.010	2583.010	588
Pole clamp		–	–	–	–	–	–	589
Cam locks	1 pc(s).	2304.000	2304.000	2304.000	–	–	–	570
Cam lock HD	1 pc(s).	2304.010	2304.010	2304.010	–	–	–	172
Lock systems		from page	from page	from page	from page	from page	from page	563

