

Ex enclosures



System accessories Page 507

Applications:

- Zone 1 and 2 or 21 and 22 to 94/9/EC
- Ambient temperature range: -30°C...+80°C
- Protection type to EN 60 079: Equipment protection due to increased safety, equipment protection due to enclosure

Material:

- Enclosure: Stainless steel 1.4301 (AISI 304)
- Cover: Stainless steel 1.4301 (AISI 304), all-round foamed-in silicone seal

Surface finish:

- Enclosure: Brushed, grain 240

Protection category IP to IEC 60 529:

- IP 66

Supply includes:

- Enclosure
- Cover

Certificates:


- PTB 03 ATEX 1013U
- IEC Ex PTB 09.0033U

Approvals:

- ATEX
- IEC

Technical details:

Available on the Internet

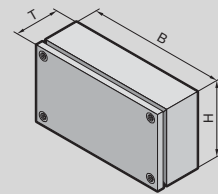

Stainless steel, empty enclosure with screw-fastened cover

Width (B) mm	Packs of	150	200	300	300	300	400	Page
Height (H) mm		150	200	150	200	300	200	
Depth (T) mm		80	80	80	80	120	120	
Model No.	1 pc(s).	9301.000	9303.000	9302.000	9304.000	9306.000	9305.000	
Weight kg		1.3	1.8	1.8	2.4	3.9	3.6	
Accessories								
Mounting plates	1 pc(s).	1560.700	1562.700	1561.700	1563.700	1567.700	1564.700	591
Wall mounting bracket	4 pc(s).	1594.000	1594.000	1594.000	1594.000	1594.000	1594.000	587
Support rails TS 35/7.5	10 pc(s).	2314.000	2315.000	2316.000	2316.000	2316.000	2317.000	614
Earth straps		see page	see page	see page	see page	see page	see page	644