

Compartment configuration

Form 1-4



Gland plates

for compartment side panel modules (internal compartmentalisation)

For closing cable entries.

Material:

- PVC, 3 mm
- Fire protection corresponding to UL 94-V0

Colour:

- RAL 7004

Supply includes:

- Assembly parts

For side panel modules height mm	Packs of	Model No.
150	10 pc(s).	9673.195
200/600	10 pc(s).	9673.192
300	4 pc(s).	9673.193
400	4 pc(s).	9673.194



Terminal box Form 4b

for modular outgoing section

For shielding the connections (terminals) of the compartment, busbar space and cable chamber in accordance with Form 4b to IEC 61 439-2. The terminal boxes are externally mounted on the compartment side panel modules in the cable chamber to match the heights of the compartments.

If necessary, a clamping strip may be mounted on the cable retainer included with the supply.

Material:

- Sheet steel, 1.5 mm

Surface finish:

- Zinc-plated

Supply includes:

- Assembly parts

Note:


- For installation of the connection spaces, the width of the cable chamber must be at least 400 mm

For compartment height mm	For cable chamber width mm	Packs of	Model No.
150	400/600	1 set(s)	9674.701
200	400/600	1 set(s)	9674.702
300	400/600	1 set(s)	9674.703
400	400/600	1 set(s)	9674.704
600	400/600	1 set(s)	9674.706



Also required:

- Compartment side panel modules for internal compartmentalisation, see page 284

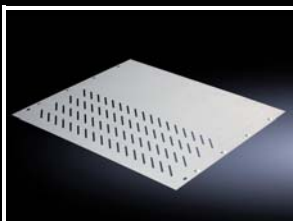

Compartment divider

- For the horizontal separation of compartments
- In combination with the side panel modules, creates form separation to Form 3 or 4

Material:

- Sheet steel, 1.25 mm

Surface finish:

- Zinc-plated

Note:

- 2 mounting brackets are required to install one compartment divider



Also required:

- Mounting bracket, see page 286



With louvres

For enclosure width mm	For compartment depth mm	Width mm	Depth mm	Packs of	Model No.
400	425	306	445	4 pc(s).	9673.444
400	600	306	588	4 pc(s).	9673.445
400	800	306	788	4 pc(s).	9673.448
600	425	506	445	4 pc(s).	9673.464
600	600	506	588	4 pc(s).	9673.465
600	800	506	788	4 pc(s).	9673.468
800	425	706	445	4 pc(s).	9673.484
800	600	706	588	4 pc(s).	9673.485
800	800	706	788	4 pc(s).	9673.488