




扫一扫看视频

### SMP-独立手指模块系列


#### 产品特点

- 按槽长度分为SMP-01 / SMP-02 / SMP-03
- 可用于手指模块[FM]与铝型材[P]间的装配
- 手指模块[FM]的安装角度和位置可自由调节
- 包含配件包 PK-SMP01

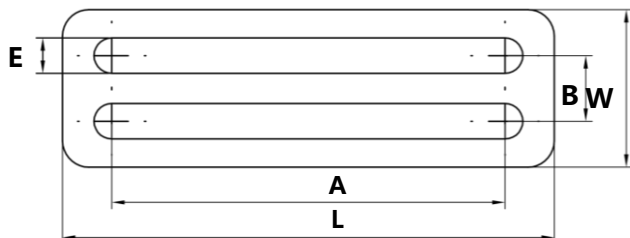

#### 配件包 PK-SMP01

- 2 x SF-081 (M4)
- 2 x SF-076 (M4x14)

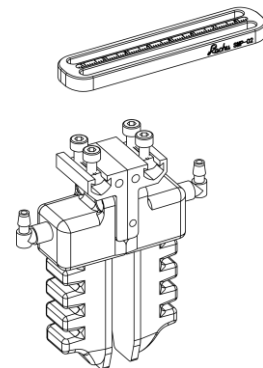


型号	槽长A [mm]	槽间距B [mm]	槽宽 E [mm]	长L [mm]	宽W [mm]	板厚 [mm]	自重[g]
SMP-01	50	10	4.2	65	20	6	10.8
SMP-02	75	10	4.2	90	20	6	16.1
SMP-03	100	10	4.2	115	20	6	18.5

### SMP-柔喙模块系列

#### 产品特点

- 按槽长度分为SMP-13/ SMP-14 / SMP-15/ SMP-16
- 可用于柔喙模块[BM], 连接组合[CM]与铝型材[P]间的装配
- 柔喙模块[BM]的安装角度和位置可自由调节
- 包含配件包 PK-SMP01

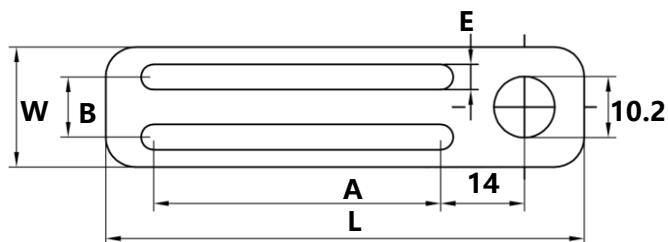

#### 配件包 PK-SMP01

- 2 x SF-081 (M4)
- 2 x SF-076 (M4x14)



型号	槽长A [mm]	槽间距B [mm]	槽宽 E [mm]	长L [mm]	宽W [mm]	板厚 [mm]	自重[g]
SMP-13	20	10	4.2	50	20	6	10.7
SMP-14	48	10	4.2	80	20	6	16.2
SMP-15	80	10	4.2	110	20	6	21.6
SMP-16	110	10	4.2	140	20	6	27.1

# 滑移安装板/ Slide Mounting Platte








扫一扫看视频

## SMP-多向系列

### 产品特点

- 按形状和槽长度分为不同款式
- 可用于手指模块[FM]与法兰连接模块[FCM]间的装配
- 手指模块[FM]的安装角度和位置可自由调节

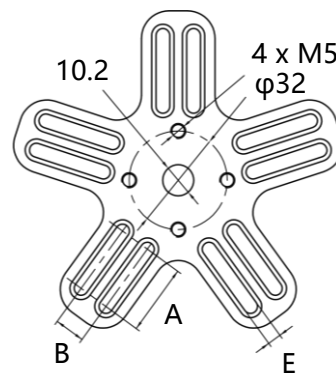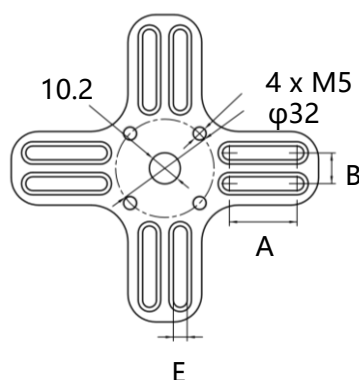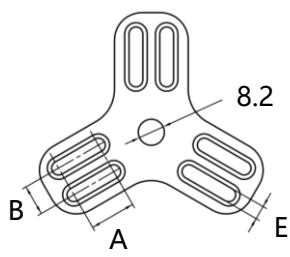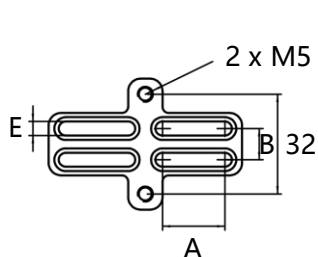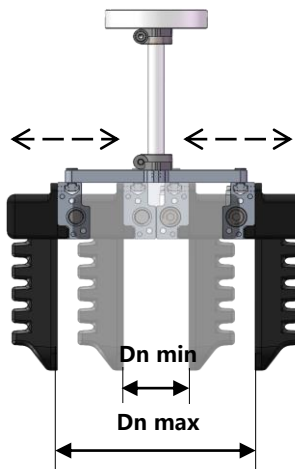

SMP-2S



SMP-3S



SMP-4S



SMP-5S



SMP-2L



SMP-3L



SMP-4L



SMP-5L

	型号	槽长 A [mm]	槽间距 B [mm]	槽宽 E [mm]	厚度 [mm]	常压指尖距 Dn [mm] Dnmin~Dnmax		自重[g]
						V2,V4手指模块	V3,V5手指模块	
双向	<b>SMP-2S</b>	20	10	4.2	8	40~69	10~37	18.9
	<b>SMP-2L</b>	45	10	4.2	8	40~119	10~87	25.4
三向	<b>SMP-3S</b>	15	10	4.2	10	58~82	28~50	42.4
	<b>SMP-3L</b>	50	10	4.2	10	58~152	28~120	73.9
四向	<b>SMP-4S</b>	22	10	4.2	10	72~104	41~72	52.3
	<b>SMP-4L</b>	67	10	4.2	10	72~194	41~162	86.2
五向	<b>SMP-5S</b>	23	10	4.2	10	91~112	53~80	94.8
	<b>SMP-5L</b>	78	10	4.2	10	91~222	53~109	179.7

\*: 夹爪组合最大夹持范围  $G_{max} = D_{nmax} + 2H_{max}$ ,  $H_{max}$  请参照手指模块参数页.