

## Combi-Säulengestelle mit unten stehenden Säulen


## Combi-die sets with down-mounted columns

## Combi-blocs à colonnes avec colonnes montées en bas

### Auswahl Gestellplatten



### Selection die set plates

### Sélection des plaques de bloc à colonnes

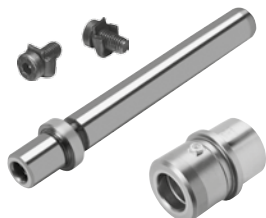

siehe Seite  
see page 4.66  
voir page

4

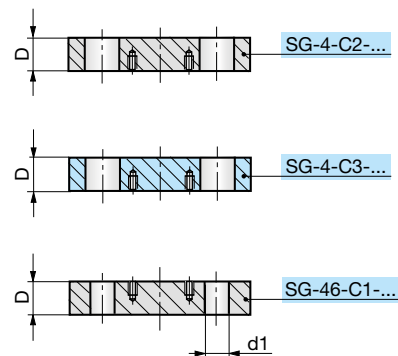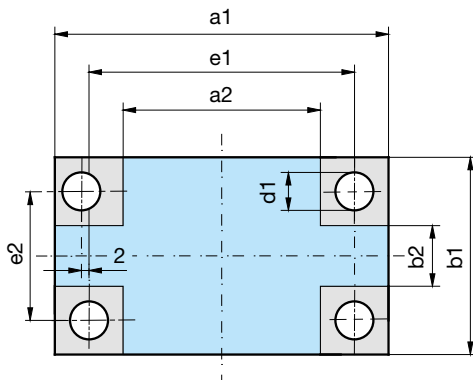

SG-46-C1-  
b1-a1-D-Mat

Mat.: 1.1730/C45W

Mat.: 3.4365 (AL)  
auf Anfrage / on request / sur demande

SG	b1	a1	C1 D	C2 D	C3 D	a2	b2	e1	e2	Ød1
SG-46-C1/ SG-4-C2/ SG-4-C3	156	156	27 / 37	27 / 37	27	48	48	100	100	20
		196	27 / 37	27 / 37	27	88	48	140	100	20
		246	27 / 37	27 / 37	27	138	48	190	100	20
		311	27 / 37	27 / 37	27	203	48	255	100	20
	196	196	27 / 37	27 / 37	27	74	74	132	132	25
		246	27 / 37	27 / 37	27	124	74	182	132	25
		311	27 / 37	27 / 37	27	189	74	247	132	25
		396	27 / 37	27 / 37	27	274	74	332	132	25
		496	37 / 47	37 / 47	27	360	60	424	124	32
		626	37 / 47	37 / 47	27	490	60	554	124	32
	246	246	37 / 47	37 / 47	27	110	110	174	174	32
		311	37 / 47	37 / 47	27	175	110	239	174	32
		396	37 / 47	37 / 47	27	260	110	324	174	32
		496	37 / 47	37 / 47	27	360	110	424	174	32
		626	47 / 57	47 / 57	27	470	90	542	162	40
		706	47 / 57	47 / 57	27	550	90	622	162	40
	311	311	37 / 47	37 / 47	27	175	175	239	239	32
		396	37 / 47	37 / 47	27	260	175	324	239	32
		496	47 / 57	47 / 57	27	340	155	412	227	40
		626	47 / 57	47 / 57	27	470	155	542	227	40
706		47 / 57	47 / 57	27	550	155	622	227	40	
796		47 / 57	47 / 57	27	640	155	712	227	40	
396	396	47 / 57	47 / 57	37	240	240	312	312	40	
	496	47 / 57	47 / 57	37	340	240	412	312	40	
	626	57 / 67	57 / 67	37	448	218	530	300	50	
	706	57 / 67	57 / 67	37	528	218	610	300	50	
	796	57 / 67	57 / 67	37	618	218	700	300	50	
496	496	57 / 67	57 / 67	37	318	318	400	400	50	
	626	57 / 67	57 / 67	37	448	318	530	400	50	
	706	57 / 67	57 / 67	37	528	318	610	400	50	
	796	57 / 67	57 / 67	37	618	318	700	400	50	
626	626	57 / 67	57 / 67	37	448	448	530	530	50	
	706	57 / 67	57 / 67	37	528	448	610	530	50	
	796	57 / 67	57 / 67	37	618	448	700	530	50	