


2

## Belüftungsventile

## Venting valves

## Soupapes

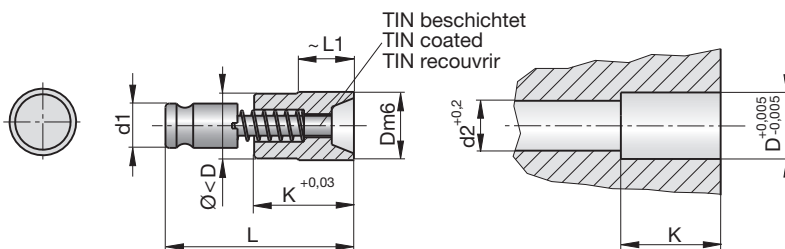

**Z5144-**

Mat.: 1.4031  
52 - 55 HRC

D	d1	d2	K	L	L1
8	6	6,75	11	24	6
12	8	9	18	34	9
18	12	14	22	45,5	12





Z5144-D



max. 200 °C  
2-9 bar

Druckluft  
Compressed air  
Air comprimé

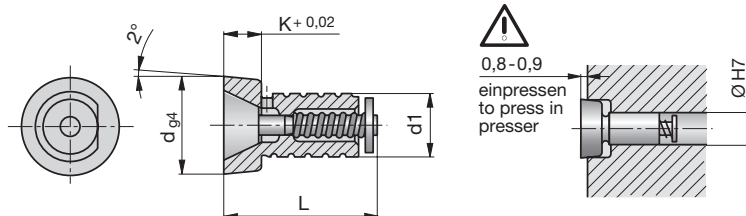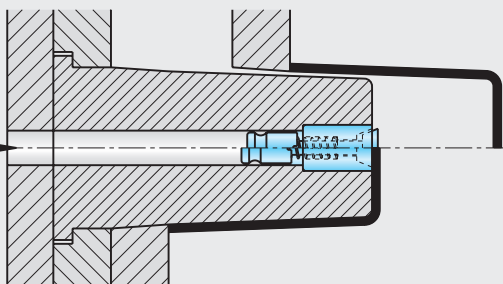

**Z5145-**

Mat.: 1.0570  
Amproloy 940

d	d1	K	L
8	6	5	16,5
12	8	5	21,3



Z5145-d



Druckluft  
Compressed air  
Air comprimé

