

## SERIES 63



### VULKOLLAN® WHEELS, FORGED STEEL CENTRE, SWIVEL TOP PLATE BRACKET TYPE EP

#### Wheel description




**Tread:** Vulkollan® polyurethane tread; hardness 93 +/-2 Shore A.

**Centre:** forged steel.

**Hub:** the housing is obtained by moulding and turning and contains ball bearings series Z.

#### Bracket description

**Extra-heavy duty bracket type EP (max. load capacity 1600 daN)**

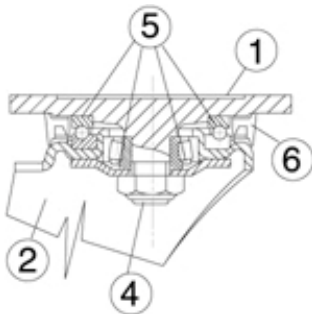

1) **Plate:** electrolytically galvanised forged steel

2) **Fork:** electrolytically galvanised steel plate

4) **Central pin:** solid with the machined plate

5) **Swivel actions:** axial ball bearing and taper roller bearing

6) **Dust seal:** orange polyethylene

**Finish:** white galvanisation

**Fitting:** top plate