


SERIES 22



STANDARD RUBBER WHEELS POLYPROPYLENE CENTRE SWIVEL BOLT HOLE BRACKET TYPE “NL”


Wheel description

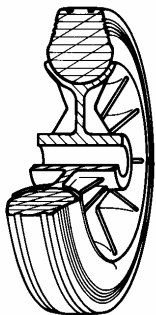

- Tread:** Standard non-marking rubber tread; hardness 80 Shore A.
Centre: polypropylene.
Hub: the hub is available with plain bore and with roller bearings.

Bracket description

Standard duty bracket type NL (max. carrying capacity 400 daN)

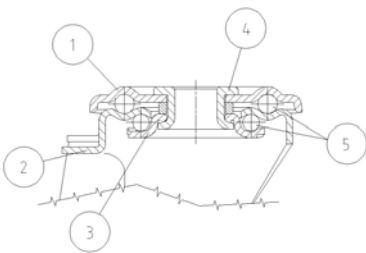

- 1) **Plate:** electrolytically galvanised steel plate
 - 2) **Fork:** electrolytically galvanised steel plate
 - 3) **Ball Racing Ring:** electrolytically galvanised steel plate
 - 4) **King Pin:** incorporated in top plate and cold riveted
 - 5) **Swivel actions:** double ring of greased balls
- Finishing:** electrolytic galvanisation
Fitting: bolt hole