


## SERIES 22



**STANDARD RUBBER WHEELS  
POLYPROPYLENE CENTRE  
FIXED BRACKET TYPE "NLX"**

### Wheel description

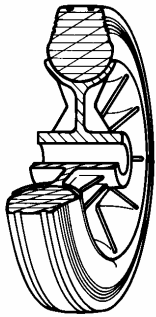


**Tread:** Standard non-marking rubber tread; hardness 80 Shore A.

**Centre:** polypropylene.

**Hub:** the hub is available with plain bore.

### Bracket description

**Standard duty bracket type NLX (max. carrying capacity 400 daN)**

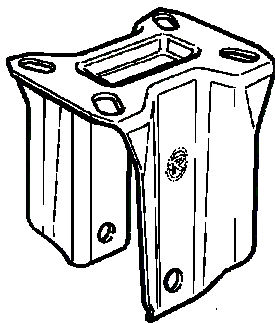

The bracket is made by AISI 304 stainless steel fork.