


SERIES 52



STANDARD RUBBER WHEELS POLYPROPYLENE CENTRE FIXED BRACKET TYPE "NL"

Wheel description

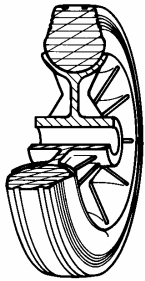


Tread: Standard rubber tread; hardness 85 +/-3 Shore A.

Centre: Polypropylene centre.

Hub: the hub is available with plain bore and with roller bearings.

Bracket description

Standard duty bracket type NL (max. carrying capacity 400 daN)

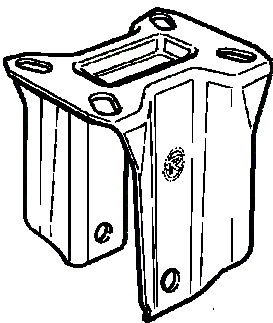

The bracket is made by an electrolytically galvanised steel fork.