

SERIES 60



INJECTION POLYURETHANE WHEELS, POLYAMIDE 6 CENTRE, FIXED BRACKET TYPE “NLX”

Wheel description




Tread: injection polyurethane tread, hardness 55 Shore D; excellent rolling resistance and elasticity, good resistant to wear and to tearing.

Centre: polyamide 6.

Hub: the hub is available with plain bearing, with stainless steel roller bearings and with stainless steel ball bearings.

Bracket description

Standard duty bracket type NLX (max. carrying capacity 400 daN)

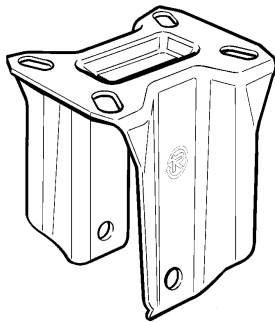

The bracket is made by AISI 304 stainless steel fork.