

SERIE 61



INJECTION POLYURETHANE WHEELS, POLYAMIDE 6 CENTRE, FIXED BRACKET TYPE “NL”

Wheel description




Tread: injection polyurethane tread, hardness 80 Shore A; excellent rolling resistance and elasticity, good resistant to wear and to tearing.

Centre: polyamide 6.

Hub: the hub is available with plain bearing, with roller bearings and with double shielding ball bearing, coprinted in the centre of the wheel.

Bracket description

Standard duty bracket type NL (max. carrying capacity 400 daN)

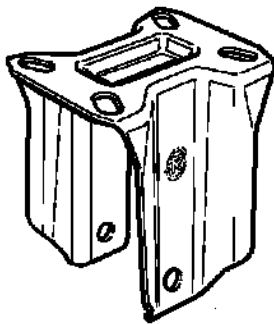

The bracket is made by an electrolytically galvanised steel fork.