
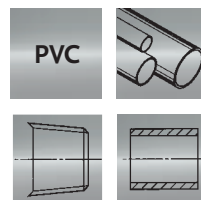
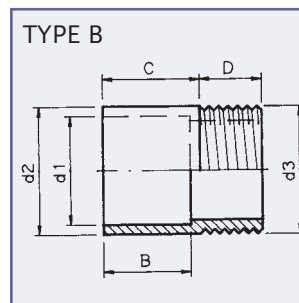
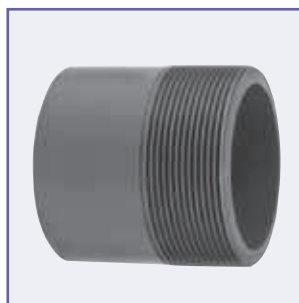
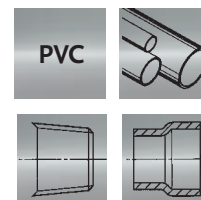


Adaptor nipple

Draadeind
 Gewindestück
 Embout fileté
 Adattore
 Nipple roscado

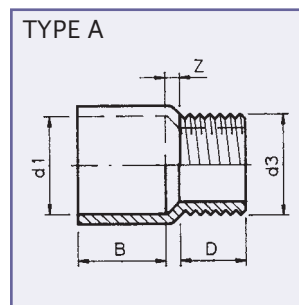

Art.code	d1	d2	d3	Z	B	C	D	Type	PN	Quantity
1.40.010	25	-	1/2" (M)	11	19	-	13	A	16	300
1.40.015	25	-	3/4" (M)	10	19	-	13	A	16	300
1.40.020	25	32	1" (M)	-	19	22	19	B	16	300
1.40.025	32	-	1/2" (M)	17	22	-	19	A	10	400
1.40.030	32	-	3/4" (M)	14	22	-	13	A	16	400
1.40.035	32	-	1" (M)	9	22	-	15	A	16	300
1.40.040	32	40	1 1/4" (M)	-	22	26	21	B	16	300
1.40.045	40	-	1" (M)	18	26	-	15	A	16	300
1.40.050	40	-	1 1/4" (M)	10	26	-	19	A	16	300
1.40.055	40	48	1 1/2" (M)	10	26	36	21	B	16	300
1.40.060	50	-	1 1/4" (M)	14	31	-	21	A	16	200
1.40.065	50	-	1 1/2" (M)	13	31	-	21	A	16	200
1.40.070	50	60	2" (M)	12	31	43	26	B	16	200
1.40.075	63	-	1 1/4" (M)	31	38	-	19	A	10	100
1.40.080	63	-	1 1/2" (M)	27	38	-	21	A	16	100
1.40.085	63	-	2" (M)	16	38	-	23	A	16	100
1.40.090	63	75	2 1/2" (M)	-	38	44	31	B	16	100
1.40.095	75	-	1 1/4" (M)	42	44	-	19	A	10	75
1.40.100	75	-	1 1/2" (M)	36	44	-	21	A	10	75
1.40.105	75	-	2" (M)	26	44	-	23	A	16	75
1.40.110	75	-	2 1/2" (M)	15	44	-	28	A	16	80
1.40.115	75	90	3" (M)	-	44	51	34	B	16	65
1.40.120	90	-	2" (M)	40	51	-	51	A	10	45
1.40.125	90	-	2 1/2" (M)	27	51	-	28	A	16	55
1.40.130	90	-	3" (M)	18	51	-	30	A	16	36
1.40.140	110	-	2 1/2" (M)	45	61	-	28	A	10	24
1.40.145	110	-	3" (M)	40	61	-	40	A	16	32
1.40.150	110	-	4" (M)	12	61	-	28	A	16	27
1.40.155	125	-	3" (M)	47	69	-	28	A	16	24
1.40.160	125	-	4" (M)	32	69	-	28	A	16	24
1.40.165	125	140	5" (M)	-	69	76	44	B	16	18
1.40.167	140	-	4" (M)	37	76	-	38	A	16	12
1.40.168	140	-	5" (M)	25	76	-	40	A	16	12
1.40.169	140	160	6" (M)	-	76	86	44	B	16	10
1.40.170	160	-	4" (M)	44	86	-	36	A	16	8
1.40.175	160	-	5" (M)	22	86	-	38	A	16	8
1.40.180	160	-	6" (M)	25	86	-	40	A	16	8
1.40.185	200	-	6" (M)	50	106	-	40	A	10	4
1.40.190	200	-	8" (M)	15	106	-	55	A	10	1