

## Adaptor union

Spuitgietskoppeling

Verschraubung


Raccord union

Bocchettone

Enlace de unión



TYPE A

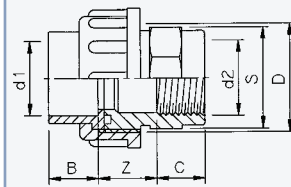


PVC



EPDM



TYPE B

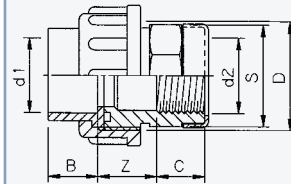

PVC



EPDM



PVC-u inch

Art.code	(inch) d1	d2	Z	B	C	D	S	Type	PN	Quantity
3.66.020	1/2	1/2" (F)	24	17	16	1"	30	A	10	100
3.66.021	1/2	1/2" (F)	24	17	16	1"	30	B	16	100
3.66.025	3/4	3/4" (F)	24	20	17	1 1/4"	36	A	10	60
3.66.026	3/4	3/4" (F)	24	20	17	1 1/4"	36	B	16	60
3.66.032	1	1" (F)	24	23	21	1 1/2"	44	A	10	100
3.66.033	1	1" (F)	24	23	21	1 1/2"	44	B	16	100
3.66.040	1 1/4	1 1/4" (F)	24	28	23	2"	54	A	10	80
3.66.041	1 1/4	1 1/4" (F)	24	28	23	2"	54	B	16	80
3.66.050	1 1/2	1 1/2" (F)	31	31	23	2 1/4"	64	A	10	60
3.66.051	1 1/2	1 1/2" (F)	31	31	23	2 1/4"	64	B	16	60
3.66.063	2	2" (F)	33	36	27	2 3/4"	80	A	10	50
3.66.064	2	2" (F)	33	36	27	2 3/4"	80	B	16	50
3.65.075	2 1/2	2 1/2" (F)	41	44	30	ZGTD	94	B	10	10
3.66.090	3	3" (F)	51	51	34	ZGTD	114	B	10	10
3.66.110	4	4" (F)	52	64	41	ZGTD	138	B	10	10

## Adaptor union with O-Ring


Koppeling met O-Ring (zwembadkoppeling)

Verschraubung mit O-Ring

Raccord union avec joint torique

Bocchettone a O-Ring

Enlace de unión con junta torica

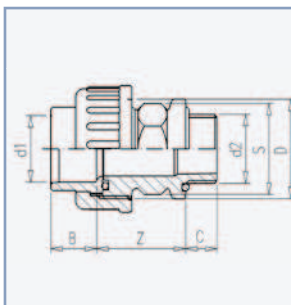

PVC



EPDM



Art.code	(inch) d1	d2	Z	B	C	D	S	PN	Quantity
3.69.022	1/2	1/2"(M)	40	17	10	1"	28	10	50
3.69.027	3/4	3/4"(M)	42	20	12	1 1/4"	32	10	60
3.69.034	1	1"(M)	43	23	15	1 1/2"	38	10	100
3.69.042	1 1/4	1 1/4"(M)	48	28	15	2"	46	10	50
3.69.052	1 1/2	1 1/2"(M)	53.5	30	18	2 1/4"	55	10	50
3.69.053	1 1/2	2"(M)	53.5	30	23.5	2 1/4"	55	10	25
3.69.065	2	2"(M)	54.5	36	23.5	2 3/4"	65	10	25