


Raccordi Femmina Sede JIC 37°

JIC Females 37° Cone

JIC 37° Dichtkegel

ISO 12151-5 (ISO 8434-2)

DKJ

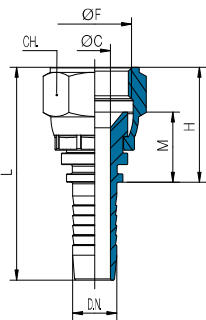

	CODICE Part n° Bestell-Nr.	Filetto Thread Gewinde	Ø F ø F ø F	DN Tubo DN Hose DN Schlauch	CH	L	Ø C	H	M
	a S 30 43 0 604 005 H	7/16" -20 UNF		3/16" 05	14	45,5	3	23,5	14
	a S 30 43 0 604 006 H	7/16" -20 UNF		1/4" 06	14	51,5	4	23,5	14
	a S 30 43 0 606 006 H	1/2" -20 UNF		1/4" 06	17	52,5	4	24,5	15
	a S 30 43 0 606 008 H	1/2" -20 UNF		5/16" 08	17	52,5	5,5	24,5	15
	a S 30 43 0 608 006 S	9/16" -18 UNF		1/4" 06	19	54,5	4	26,5	16,5
	a S 30 43 0 608 008	9/16" -18 UNF		5/16" 08	19	55	5,5	27	17
	a S 30 43 0 608 010	9/16" -18 UNF		3/8" 10	19	56	7	26,5	16,5
	a S 30 43 0 610 010	3/4" -16 UNF		3/8" 10	24	60	7	30,5	19
	a S 30 43 0 610 013 A	3/4" -16 UNF		1/2" 12	24	59,5	9,5	30	18,5
	a S 30 43 0 610 016	3/4" -16 UNF		5/8" 16	24	64,5	12,5	31,5	20
NEW	a S 30 43 0 610 019	3/4" -16 UNF		3/4" 19	24	72,5	15	33,5	22
	a S 30 43 0 613 019	7/8" -14 UNF		3/4" 19	27	75,5	15	36,5	23,5
	a S 30 43 0 613 010	7/8" -14 UNF		3/8" 10	27	63	7	33,5	20
	a S 30 43 0 613 013 A	7/8" -14 UNF		1/2" 12	27	64,5	9,5	35	21
NEW	a S 30 43 0 613 016 A	7/8" -14 UNF		5/8" 16	27	67,5	12,5	33,5	19,5
	a S 30 43 0 613 019	7/8" -14 UNF		3/4" 19	27	75,5	15	36,5	23,5
	a S 30 43 0 619 013 A	1 1/16" - 12 UN		1/2" 12	32	67	9,5	37,5	21,5
	a S 30 43 0 619 016 A	1 1/16" - 12 UN		5/8" 16	32	72	12,5	38	22
	a S 30 43 0 619 019 A	1 1/16" - 12 UN		3/4" 19	32	79	15	40	24
	a S 30 43 0 619 025 A	1 1/16" - 12 UN		1" 25	32	87	15	40	24
	a S 30 43 0 622 019 A	1 3/16" - 12 UN		3/4" 19	36	80,5	15	41,5	25
	a S 30 43 0 625 019 A	1 5/16" - 12 UN		3/4" 19	41	81	15	42	25
	a S 30 43 0 625 025 A	1 5/16" - 12 UN		1" 25	41	89	19,5	42	25
	a S 30 43 0 632 025 A	1 5/8" - 12 UN		1" 25	50	90,5	19,5	43,5	27
	a S 30 43 0 632 032 A	1 5/8" - 12 UN		1 1/4" 31	50	98,5	26	44	27,5
	a S 30 43 0 638 032 A	1 7/8" - 12 UN		1 1/4" 31	60	103,5	26	49	29,5
	a S 30 43 0 638 038 A	1 7/8" - 12 UN		1 1/2" 38	60	107	32	49	29,5
	a S 30 43 0 650 050 A	2 1/2" - 12 UN		2" 51	75	131,5	42	59	35,5

a: dado pressato

a: crimped nut

a: verkrimpte Überwurfmutter