


Flange tipo Caterpillar®  
Flanges Type Caterpillar®  
Flanschanschlüsse Typ Caterpillar®


ISO 12151-3 (ISO 6162-2)

## FLCAT

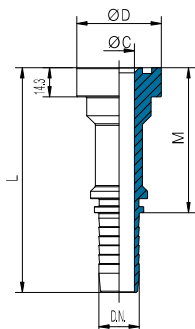


CODICE Part n° Bestell-Nr.	DN FLANGIA DN Flange DN Flansch	DN Tubo DN Hose DN Schlauch	L	Ø C	H	M	Ø D
S 30 21 6 019 019 A	3/4"	3/4" 19	110	15		71	41,3
S 30 21 6 025 019 A	1"	3/4" 19	114,5	15		75,5	47,6
S 30 21 6 025 025 A	1"	1" 25	127	19,5		80	47,6
S 30 21 6 032 025 A	1 1/4"	1" 25	131,5	19,5		84,5	54
S 30 21 6 032 032 A	1 1/4"	1 1/4" 31	143,5	26		89	54
S 30 21 6 038 032 A	1 1/2"	1 1/4" 31	148	26		93,5	63,5
S 30 21 6 038 038 A	1 1/2"	1 1/2" 38	156	32		98	63,5

## FLCAT 90

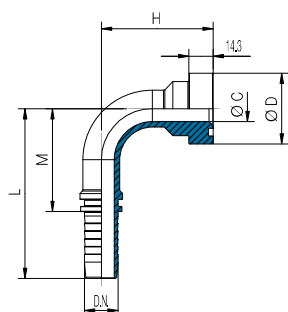

S 30 22 6 019 019 A	3/4"	3/4" 19	99	15	66,5	60	41,3
S 30 22 6 025 019 A	1"	3/4" 19	99	15	71,5	60	47,6
S 30 22 6 025 025 A	1"	1" 25	126	19,5	79	79	47,6
S 30 22 6 032 025 A	1 1/4"	1" 25	126	19,5	85,5	79	54
S 30 22 6 032 032 A	1 1/4"	1 1/4" 31	150,5	26	94,5	96	54
S 30 22 6 038 032 A	1 1/2"	1 1/4" 31	150,5	26	100,5	96	63,5
S 30 22 6 038 038 A	1 1/2"	1 1/2" 38	175,5	32	110	117,5	63,5

## FLCAT 45

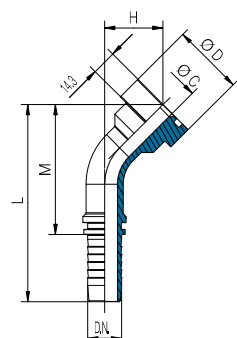

S 30 23 6 019 019 A	3/4"	3/4" 19	114	15	34,5	75	41,3
S 30 23 6 025 019 A	1"	3/4" 19	118	15	38,5	79	47,6
S 30 23 6 025 025 A	1"	1" 25	140,5	19,5	38,5	93,5	47,6
S 30 23 6 032 025 A	1 1/4"	1" 25	145	19,5	43	98	54
S 30 23 6 032 032 A	1 1/4"	1 1/4" 31	167	26	47	112,5	54
S 30 23 6 038 032 A	1 1/2"	1 1/4" 31	171	26	51,5	116,5	63,5
S 30 23 6 038 038 A	1 1/2"	1 1/2" 38	191	32	53	133	63,5

Articoli di basso consumo su richiesta  
Slow moving articles available on request  
Artikel mit geringen Stückzahlen auf Anfrage