


Union elbows

Tube coupling: VOSS Lok⁴⁰

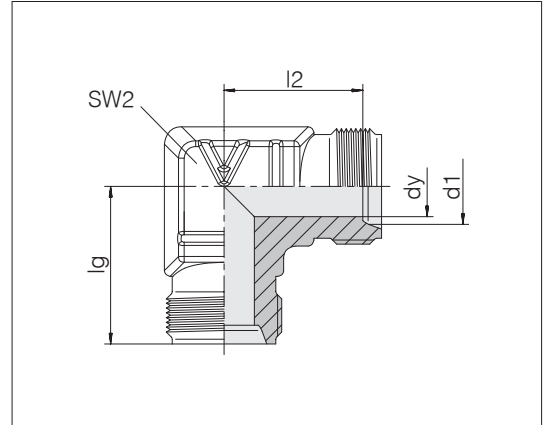

Tube OD d1	dy	lg	l2	SW2	kg/100 ca.	Order-No.	Designation
6	4.5	20	17.4	12	2.4	7000960700	40-E-6-SST
8	6.5	21.5	18.8	14	3.3	7000960800	40-E-8-SST
10	8	23.5	20.5	17	5.7	7000960900	40-E-10-SST
12	9.5	27	23.9	19	8.9	7000961000	40-E-12-SST
14	11.5	30	26.8	22	13.3	7000961100	40-E-14-SST
15	12	30	26.7	22	12.8	7000961200	40-E-15-SST
16	13	30	26.5	22	11.8	7000961300	40-E-16-SST
18	15	32.3	28.7	27	19.2	7000961400	40-E-18-SST
20	16	33.7	30	30	26.2	7000961500	40-E-20-SST
22	18	33.7	29.7	30	23.2	7000961600	40-E-22-SST